



PERFORMANCE FEATURES:


- Provides extra protection against dirt and dust
- Creates separation between areas
- Clip shelves make for easy bolt-free assembly and adjustment
- Shelves are adjustable on 1" increments
- Panels on side and back provide stability

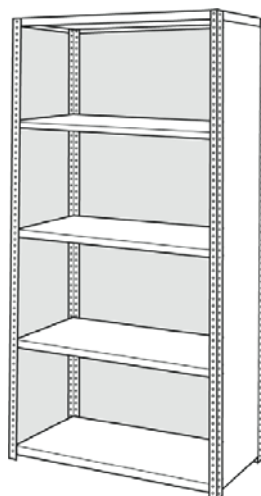

**5 SHELF
STARTER KITS**

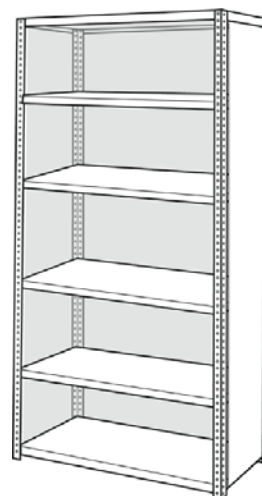

**6 SHELF
STARTER KITS**

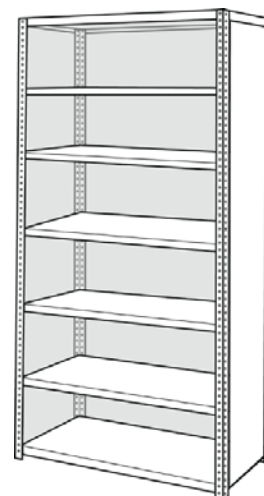

**7 SHELF
STARTER KITS**

Additional Shelves and Clips available, see **pgs. 94 & 100**.
22 Gauge Shelving also available in three different sizes, see **pg. 102**.

SHELF D" x W"	75"H				87"H				99"H			
	18 GAUGE		20 GAUGE		18 GAUGE		20 GAUGE		18 GAUGE		20 GAUGE	
	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT
5 Shelf, 75"H Open Shelving Unit												
12" x 36"	CL18G-75-1236-5	98 lbs	CL20G-75-1236-5	90 lbs	CL18G-87-1236-5	116 lbs	CL20G-87-1236-5	108 lbs	CL18G-99-1236-5	118 lbs	CL20G-99-1236-5	110 lbs
15" x 36"	CL18G-75-1536-5	112 lbs	CL20G-75-1536-5	95 lbs	CL18G-87-1536-5	131 lbs	CL20G-87-1536-5	114 lbs	CL18G-99-1536-5	133 lbs	CL20G-99-1536-5	116 lbs
18" x 36"	CL18G-75-1836-5	126 lbs	CL20G-75-1836-5	107 lbs	CL18G-87-1836-5	148 lbs	CL20G-87-1836-5	129 lbs	CL18G-99-1836-5	150 lbs	CL20G-99-1836-5	131 lbs
24" x 36"	CL18G-75-2436-5	150 lbs	CL20G-75-2436-5	127 lbs	CL18G-87-2436-5	174 lbs	CL20G-87-2436-5	151 lbs	CL18G-99-2436-5	176 lbs	CL20G-99-2436-5	153 lbs
30" x 36"	CL18G-75-3036-5	170 lbs	CL20G-75-3036-5	143 lbs	CL18G-87-3036-5	196 lbs	CL20G-87-3036-5	169 lbs	CL18G-99-3036-5	198 lbs	CL20G-99-3036-5	171 lbs
12" x 42"	CL18G-75-1242-5	114 lbs	CL20G-75-1242-5	102 lbs	CL18G-87-1242-5	134 lbs	CL20G-87-1242-5	123 lbs	CL18G-99-1242-5	136 lbs	CL20G-99-1242-5	125 lbs
15" x 42"	CL18G-75-1542-5	125 lbs	CL20G-75-1542-5	106 lbs	CL18G-87-1542-5	146 lbs	CL20G-87-1542-5	127 lbs	CL18G-99-1542-5	148 lbs	CL20G-99-1542-5	129 lbs
18" x 42"	CL18G-75-1842-5	138 lbs	CL20G-75-1842-5	117 lbs	CL18G-87-1842-5	161 lbs	CL20G-87-1842-5	139 lbs	CL18G-99-1842-5	163 lbs	CL20G-99-1842-5	141 lbs
24" x 42"	CL18G-75-2442-5	167 lbs	CL20G-75-2442-5	137 lbs	CL18G-87-2442-5	192 lbs	CL20G-87-2442-5	162 lbs	CL18G-99-2442-5	194 lbs	CL20G-99-2442-5	164 lbs
30" x 42"	CL18G-75-3042-5	191 lbs	CL20G-75-3042-5	153 lbs	CL18G-87-3042-5	220 lbs	CL20G-87-3042-5	183 lbs	CL18G-99-3042-5	222 lbs	CL20G-99-3042-5	184 lbs
12" x 48"	CL18G-75-1248-5	129 lbs	CL20G-75-1248-5	116 lbs	CL18G-87-1248-5	153 lbs	CL20G-87-1248-5	140 lbs	CL18G-99-1248-5	155 lbs	CL20G-99-1248-5	142 lbs
15" x 48"	CL18G-75-1548-5	141 lbs	CL20G-75-1548-5	121 lbs	CL18G-87-1548-5	165 lbs	CL20G-87-1548-5	144 lbs	CL18G-99-1548-5	167 lbs	CL20G-99-1548-5	147 lbs
18" x 48"	CL18G-75-1848-5	152 lbs	CL20G-75-1848-5	128 lbs	CL18G-87-1848-5	178 lbs	CL20G-87-1848-5	154 lbs	CL18G-99-1848-5	180 lbs	CL20G-99-1848-5	156 lbs
24" x 48"	CL18G-75-2448-5	184 lbs	CL20G-75-2448-5	153 lbs	CL18G-87-2448-5	213 lbs	CL20G-87-2448-5	181 lbs	CL18G-99-2448-5	215 lbs	CL20G-99-2448-5	183 lbs
30" x 48"	CL18G-75-3048-5	209 lbs	CL20G-75-3048-5	175 lbs	CL18G-87-3048-5	240 lbs	CL20G-87-3048-5	205 lbs	CL18G-99-3048-5	242 lbs	CL20G-99-3048-5	207 lbs
6 Shelf, 75"H Open Shelving Unit												
12" x 36"	CL18G-75-1236-6	106 lbs	CL20G-75-1236-6	97 lbs	CL18G-87-1236-6	124 lbs	CL20G-87-1236-6	115 lbs	CL18G-99-1236-6	126 lbs	CL20G-99-1236-6	117 lbs
15" x 36"	CL18G-75-1536-6	123 lbs	CL20G-75-1536-6	103 lbs	CL18G-87-1536-6	142 lbs	CL20G-87-1536-6	122 lbs	CL18G-99-1536-6	144 lbs	CL20G-99-1536-6	124 lbs
18" x 36"	CL18G-75-1836-6	138 lbs	CL20G-75-1836-6	114 lbs	CL18G-87-1836-6	161 lbs	CL20G-87-1836-6	137 lbs	CL18G-99-1836-6	163 lbs	CL20G-99-1836-6	139 lbs
24" x 36"	CL18G-75-2436-6	166 lbs	CL20G-75-2436-6	138 lbs	CL18G-87-2436-6	190 lbs	CL20G-87-2436-6	162 lbs	CL18G-99-2436-6	192 lbs	CL20G-99-2436-6	164 lbs
30" x 36"	CL18G-75-3036-6	189 lbs	CL20G-75-3036-6	157 lbs	CL18G-87-3036-6	215 lbs	CL20G-87-3036-6	183 lbs	CL18G-99-3036-6	217 lbs	CL20G-99-3036-6	185 lbs
12" x 42"	CL18G-75-1242-6	125 lbs	CL20G-75-1242-6	111 lbs	CL18G-87-1242-6	145 lbs	CL20G-87-1242-6	131 lbs	CL18G-99-1242-6	147 lbs	CL20G-99-1242-6	133 lbs
15" x 42"	CL18G-75-1542-6	137 lbs	CL20G-75-1542-6	115 lbs	CL18G-87-1542-6	158 lbs	CL20G-87-1542-6	135 lbs	CL18G-99-1542-6	160 lbs	CL20G-99-1542-6	137 lbs
18" x 42"	CL18G-75-1842-6	151 lbs	CL20G-75-1842-6	125 lbs	CL18G-87-1842-6	175 lbs	CL20G-87-1842-6	149 lbs	CL18G-99-1842-6	177 lbs	CL20G-99-1842-6	151 lbs
24" x 42"	CL18G-75-2442-6	185 lbs	CL20G-75-2442-6	149 lbs	CL18G-87-2442-6	211 lbs	CL20G-87-2442-6	175 lbs	CL18G-99-2442-6	213 lbs	CL20G-99-2442-6	177 lbs
30" x 42"	CL18G-75-3042-6	213 lbs	CL20G-75-3042-6	167 lbs	CL18G-87-3042-6	242 lbs	CL20G-87-3042-6	196 lbs	CL18G-99-3042-6	244 lbs	CL20G-99-3042-6	198 lbs
12" x 48"	CL18G-75-1248-6	141 lbs	CL20G-75-1248-6	125 lbs	CL18G-87-1248-6	165 lbs	CL20G-87-1248-6	149 lbs	CL18G-99-1248-6	167 lbs	CL20G-99-1248-6	151 lbs
15" x 48"	CL18G-75-1548-6	154 lbs	CL20G-75-1548-6	130 lbs	CL18G-87-1548-6	179 lbs	CL20G-87-1548-6	155 lbs	CL18G-99-1548-6	181 lbs	CL20G-99-1548-6	157 lbs
18" x 48"	CL18G-75-1848-6	168 lbs	CL20G-75-1848-6	140 lbs	CL18G-87-1848-6	194 lbs	CL20G-87-1848-6	165 lbs	CL18G-99-1848-6	196 lbs	CL20G-99-1848-6	167 lbs
24" x 48"	CL18G-75-2448-6	205 lbs	CL20G-75-2448-6	167 lbs	CL18G-87-2448-6	233 lbs	CL20G-87-2448-6	196 lbs	CL18G-99-2448-6	235 lbs	CL20G-99-2448-6	198 lbs
30" x 48"	CL18G-75-3048-6	234 lbs	CL20G-75-3048-6	192 lbs	CL18G-87-3048-6	265 lbs	CL20G-87-3048-6	223 lbs	CL18G-99-3048-6	267 lbs	CL20G-99-3048-6	225 lbs
7 Shelf, 75"H Open Shelving Unit												
12" x 36"	CL18G-75-1236-7	115 lbs	CL20G-75-1236-7	104 lbs	CL18G-87-1236-7	132 lbs	CL20G-87-1236-7	122 lbs	CL18G-99-1236-7	134 lbs	CL20G-99-1236-7	124 lbs
15" x 36"	CL18G-75-1536-7	134 lbs	CL20G-75-1536-7	110 lbs	CL18G-87-1536-7	153 lbs	CL20G-87-1536-7	129 lbs	CL18G-99-1536-7	155 lbs	CL20G-99-1536-7	131 lbs
18" x 36"	CL18G-75-1836-7	151 lbs	CL20G-75-1836-7	124 lbs	CL18G-87-1836-7	173 lbs	CL20G-87-1836-7	146 lbs	CL18G-99-1836-7	175 lbs	CL20G-99-1836-7	148 lbs
24" x 36"	CL18G-75-2436-7	182 lbs	CL20G-75-2436-7	151 lbs	CL18G-87-2436-7	206 lbs	CL20G-87-2436-7	173 lbs	CL18G-99-2436-7	207 lbs	CL20G-99-2436-7	175 lbs
30" x 36"	CL18G-75-3036-7	208 lbs	CL20G-75-3036-7	171 lbs	CL18G-87-3036-7	234 lbs	CL20G-87-3036-7	197 lbs	CL18G-99-3036-7	236 lbs	CL20G-99-3036-7	199 lbs
12" x 42"	CL18G-75-1242-7	136 lbs	CL20G-75-1242-7	120 lbs	CL18G-87-1242-7	156 lbs	CL20G-87-1242-7	140 lbs	CL18G-99-1242-7	158 lbs	CL20G-99-1242-7	142 lbs
15" x 42"	CL18G-75-1542-7	150 lbs	CL20G-75-1542-7	123 lbs	CL18G-87-1542-7	171 lbs	CL20G-87-1542-7	144 lbs	CL18G-99-1542-7	173 lbs	CL20G-99-1542-7	146 lbs
18" x 42"	CL18G-75-1842-7	166 lbs	CL20G-75-1842-7	136 lbs	CL18G-87-1842-7	189 lbs	CL20G-87-1842-7	159 lbs	CL18G-99-1842-7	191 lbs	CL20G-99-1842-7	161 lbs
24" x 42"	CL18G-75-2442-7	203 lbs	CL20G-75-2442-7	161 lbs	CL18G-87-2442-7	229 lbs	CL20G-87-2442-7	187 lbs	CL18G-99-2442-7	231 lbs	CL20G-99-2442-7	189 lbs
30" x 42"	CL18G-75-3042-7	235 lbs	CL20G-75-3042-7	182 lbs	CL18G-87-3042-7	264 lbs	CL20G-87-3042-7	211 lbs	CL18G-99-3042-7	266 lbs	CL20G-99-3042-7	213 lbs
12" x 48"	CL18G-75-1248-7	153 lbs	CL20G-75-1248-7	135 lbs	CL18G-87-1248-7	177 lbs	CL20G-87-1248-7	159 lbs	CL18G-99-1248-7	179 lbs	CL20G-99-1248-7	163 lbs
15" x 48"	CL18G-75-1548-7	168 lbs	CL20G-75-1548-7	140 lbs	CL18G-87-1548-7	193 lbs	CL20G-87-1548-7	165 lbs	CL18G-99-1548-7	195 lbs	CL20G-99-1548-7	167 lbs
18" x 48"	CL18G-75-1848-7	184 lbs	CL20G-75-1848-7	151 lbs	CL18G-87-1848-7	210 lbs	CL20G-87-1848-7	177 lbs	CL18G-99-1848-7	212 lbs	CL20G-99-1848-7	179 lbs
24" x 48"	CL18G-75-2448-7	225 lbs	CL20G-75-2448-7	181 lbs	CL18G-87-2448-7	254 lbs	CL20G-87-2448-7	210 lbs	CL18G-99-2448-7	256 lbs	CL20G-99-2448-7	212 lbs
30" x 48"	CL18G-75-3048-7	259 lbs	CL20G-75-3048-7	210 lbs	CL18G-87-3048-7	289 lbs	CL20G-87-3048-7	241 lbs	CL18G-99-3048-7	291 lbs	CL20G-99-3048-7	243 lbs