

Wiha TORXPlus® Insert Bits and Power Bits


TORXPlus®

Made in Germany -
Production Quality

Highly resistant
to wear and
tear for a
long tool
life

Impact resistant modified
CVM, tool steel, hardened

Suitable for all applications for both
manual & machine Hardness HRC 59-61

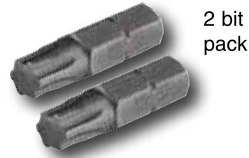




2 bit
pack




 
 
716 TORXPlus® Insert Bit Packs, 1"

CVM S2 modified tool steel

Item			
No.	Size	mm	lbs.
71631	IP3	25	.03
71632	IP4	25	.03
71633	IP5	25	.03
71634	IP6	25	.03
71635	IP7	25	.03
71636	IP8	25	.03
71637	IP9	25	.03
71638	IP10	25	.03
71639	IP15	25	.03
71641	IP20	25	.03
71642	IP25	25	.03
71643	IP27	25	.03
71644	IP30	25	.03
71645	IP40	25	.04


 



716 TORXPlus® Insert Bits, 1/4" Hex, 1"

Item			
No.	Size	mm	pkg. lbs.
71603	IP3	25	10 .12
71604	IP4	25	10 .12
71605	IP5	25	10 .12
71606	IP6	25	10 .12
71607	IP7	25	10 .12
71608	IP8	25	10 .12
71609	IP9	25	10 .12
71610	IP10	25	10 .12
71615	IP15	25	10 .12
71620	IP20	25	10 .12
71625	IP25	25	10 .12
71627	IP27	25	10 .13
71630	IP30	25	10 .13
71640	IP40	25	10 .15



746 TORXPlus® Power Bits, 1/4" Hex, 2"


 

Item			
No.	Size	mm	pkg. lbs.
74601	IP5	50	10 .18
74602	IP6	50	10 .18
74603	IP7	50	10 .18
74604	IP8	50	10 .18
74608	IP9	50	10 .18
74612	IP10	50	10 .20
74616	IP15	50	10 .20
74620	IP20	50	10 .20
74624	IP25	50	10 .20
74628	IP27	50	10 .25
74632	IP30	50	10 .25
74636	IP40	50	10 .25



2 bit
pack



746 TORXPlus® Power Bit Packs, 2"

Item			
No.	Size	mm	lbs.
74611	IP1	50	.05
74613	IP2	50	.05
74614	IP3	50	.05
74617	IP4	50	.05
74659	IP5	50	.05
74660	IP6	50	.05
74661	IP7	50	.05
74662	IP8	50	.05
74663	IP9	50	.05
74664	IP10	50	.05
74665	IP15	50	.05
74666	IP20	50	.05
74667	IP25	50	.05
74668	IP27	50	.05
74669	IP30	50	.05
74670	IP40	50	.05

Wiha Ball End TORX® Bits


 



See additional Ball End TORX
Tools on Page 15

Wiha Security Pentalobe 5 Point Insert Bit





716 Security Pentalobe 5 Point Insert Bits, 1/4" Hex, 1" OAL

Item			
No.	Size	mm	pkg. lbs.
71648	PLS8	25	1 .11
71650	PLS10	25	1 .11
71652	PLS15	25	1 .11
71654	PLS20	25	1 .12
71656	PLS25	25	1 .13
71657	PLS27	25	1 .13
71658	PLS30	25	1 .14
71660	PLS40	35	1 .14



XSelector
Pocket Sized
3 1/8" x 2 1/8" x 1/2"

79450 XSelector Bit Set With Security Pentalobe 5 Point Bits

 Set Includes Quick Release Holder
lbs. and the following 7 bits:
.18  Security Pentalobe 5 Point Sizes:
PLS8, PLS10, PLS15, PLS20,
PLS25, PLS27, PLS30

Wiha TORX® MagicSpring Screw Holding Power Bits


 

Screw Holding
TORX Bits



Stainless
rotary spring

2 bit pack

745 TORX® MagicSpring Screw Holding Power Bits, 1/4" Hex Drive, 2.0"/50mm OAL

Item			
No.	Size	mm	pkg. lbs.
74552	T10	50	2 .05
74554	T15	50	2 .05
74555	T20	50	2 .05
74557	T25	50	2 .05
74562	T30	50	2 .05
74564	T40	50	2 .05