


6-Lobe Pin



6-Lobe Pin - Countersunk Self Tapping Screws - A2 Stainless Steel

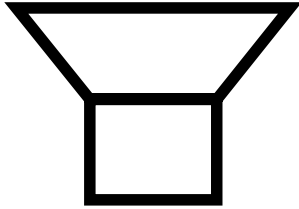

Head Dimensions

SCREW TYPE 6-LOBE PIN	DIMENSIONS	AB TYPE SELF TAPPING SCREWS					
		No. 4	No. 6	No. 8	No. 10	No. 12	No. 14
		2.9mm	3.5mm	4.2mm	4.8mm	5.5mm	6.3mm
COUNTERSUNK HEAD		4.9	6.6	7.9	9.3	10.6	12.4
		1.5	2.1	2.5	3.0	3.4	3.8

Material and Finish

Material: A2 Stainless Steel

Heat Treatment: None

Finish: Passivated

Part Numbers & Driver Size

GAUGE	LENGTH	3/8"	1/2"	5/8"	3/4"	1"	1 1/4"	1 1/2"	1-3/4"	2"	2 1/2"	3"	4"	DRIVER SIZE
		9.5mm	13mm	16mm	19mm	25mm	32mm	38mm	44mm	50mm	63mm	75mm	100mm	
4	2.9mm		RTCS04D	RTCS04E	RTCS04F	RTCS04G								T10
6	3.5mm		RTCS06D	RTCS06E	RTCS06F	RTCS06G	RTCS06H	RTCS06I						T15
8	4.2mm	RTCS08C	RTCS08D	RTCS08E	RTCS08F	RTCS08G	RTCS08H	RTCS08I	RTCS08IA	RTCS08J	RTCS08K			T20
10	4.8mm		RTCS10D	RTCS10E	RTCS10F	RTCS10G	RTCS10H	RTCS10I		RTCS10J	RTCS10K	RTCS10L	RTCS10N	T25
12	5.5mm				RTCS12F	RTCS12G	RTCS12H	RTCS12I		RTCS12J	RTCS12K	RTCS12L		T27
14	6.3mm				RTCS14F	RTCS14G	RTCS14H	RTCS14I		RTCS14J				T30

Additional Information

Installation: 6-Lobe Pin - see video

Removal: 2-Way Removable Screw

- ✓ 6-Lobe drive with internal pin
- ✓ High torque drive
- ✓ Available in multiple heads & threads
- ✓ Stocked in the largest range available



Every effort has been made to ensure the accuracy of information provided in this datasheet. Hafren Fasteners cannot warrant the information however, expressly or implied, and any liability arising from it is expressly excluded. Customers must satisfy themselves as to the suitability of products and the technical information relating to them, and it is recommended that you conduct your own tests to establish suitability. All sizes shown are in mm without min and max tolerances and are guide sizes. Hafren Fasteners reserve the right to change/alter sizes without notice. This does not effect your statutory rights.




Weight per Pack

GAUGE	LENGTH	1/2"	1/2"	5/8"	3/4"	1"	1 1/4"	1 1/2"	1-3/4"	2"	2 1/2"	3"	4"	DRIVER SIZE
		9.5mm	13mm	16mm	19mm	25mm	32mm	38mm	44mm	50mm	63mm	75mm	100mm	
4	2.9mm		Box 9 55g	Box 9 53g	Box 9 75g	Box 9 90g								T10
6	3.5mm		Box 9 85g	Box 9 105g	Box 9 116g	Box 9 149g	Box 12 175g	Box 12 213g						T15
8	4.2mm	Box 9 98g	Box 9 118g	Box 9 144g	Box 9 172g	Box 12 208g	Box 12 254g	Box 18 301g	Box 18 344g	Box 18 387g	Box 22 490g			T20
10	4.8mm		Box 9 203g	Box 9 210g	Box 9 225g	Box 12 296g	Box 18 355g	Box 18 418g		Box 22 530g	Box 22 645g	Box 27 760g	Box 30 1,010g	T25
12	5.5mm				Box 12 296g	Box 18 382g	Box 18 424g	Box 18 517g		Box 22 705g	Box 27 862g	Box 27 1,026g		T27
14	6.3mm				Box 18 423g	Box 18 601	Box 18 743g	Box 22 848g		Box 22 1,060g				T30

Pack Dimensions Guide

DIMENSION	BOX SIZE	BOX 9	BOX 12	BOX 18	BOX 22	BOX 27	BOX 30	BOX 32
	A		51mm	57mm	71mm	81mm	89mm	101mm
B		32mm	36mm	47mm	54mm	68mm	76mm	82mm
C		55mm	66mm	90mm	111mm	124mm	128mm	171mm

Cardboard Box

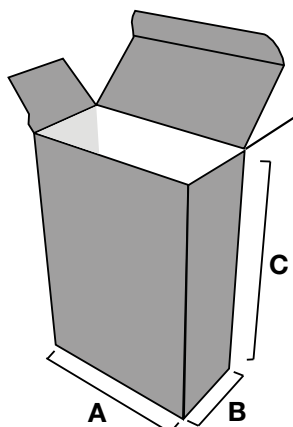

Every effort has been made to ensure the accuracy of information provided in this datasheet. Hafren Fasteners cannot warrant the information however, expressly or implied, and any liability arising from it is expressly excluded. Customers must satisfy themselves as to the suitability of products and the technical information relating to them, and it is recommended that you conduct your own tests to establish suitability. All sizes shown are in mm without min and max tolerances and are guide sizes. Hafren Fasteners reserve the right to change/alter sizes without notice. This does not effect your statutory rights.