


## LED Spotlights

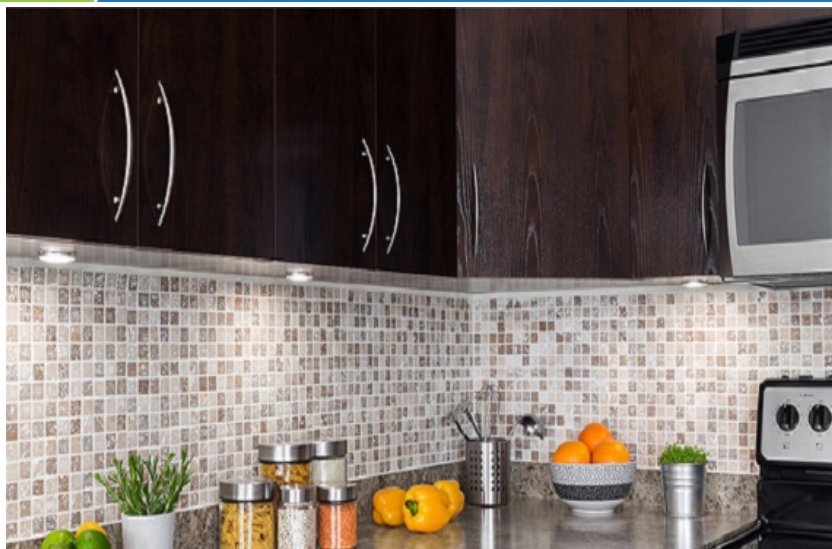

VT-247D

### HIGHLIGHTS :

WATTS



6.5

EQ. WATTS



55

LUMINOUS



450

BEAM ANGLE



110

Item No	:	VT-247D
SKU Code	:	200
Watts	:	6.5
EQ. Watts	:	55
Base / holder	:	GU10
Voltage	:	AC:220-240V,50Hz
Lumen(lm)	:	450
Color Temperature	:	6400K
Beam Angle	:	110
PF	:	>0.5
LED Chip Type	:	SMD-Samsung Chip
CRI	:	>80
Energy rating label	:	A+
IP Rating Protection Class	:	IP20
Body type	:	Plastic
Dimmable	:	Yes
Life Time	:	30,000 Hours
EAN code	:	3800157631655
Unit size	:	ø50x 55mm
Packing details	:	200.00

### PRODUCT FEATURES