


**EAO AG**

Tannwaldstrasse 88

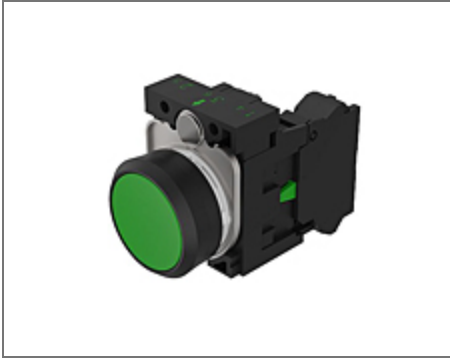
4600 Olten

Switzerland

**Phone:** +41 62 286 9111

[info@eao.com](mailto:info@eao.com)

## Part No. 45-1131.1150.000.401, Pushbutton


[Specifications](#) | [Bill of Materials](#)

### Specifications

Actuator	<u>Pushbutton</u>
Lens Colour	Green
Function	2 Positions, momentary (O<l)
Housing Material	Plastic
Shape of Handle or Frontring	raised/ level to bezel
Lock System	None
Key	None
Key Type	None
Switching Angle	None
Contacts	1NO
Terminal	Spring-loaded terminal
Voltage Illumination	None

Mounting Type	Front mounting
Mounting Style	Holder
Environmental Rating	IP66, IP67, IP69K
Industry Standards/Certifications	UL, CSA, VDE, CCC, CE, RoHS
Switching Function	On-Off
Illumination	None
Contact Material	Silver
Termination Style	Spring type
Mechanical Life	Maintain 500'000 switching cycles Momentary 10'000'000 switching cycles
AC Voltage	500 V
DC Voltage	500 V
Switching Current	10 A

## Bill of Materials

Actuator	45-2131.1150.000
Holder	45-2300.1000.000
Switch Element 1	45-311.1Z40