




**EAO AG**  
Tannwaldstrasse 88  
4600 Olten  
Switzerland

**Phone:** +41 62 286 9111  
[info@eao.com](mailto:info@eao.com)

## Part No. 45-1231.31E6.000.402, Illuminated Pushbutton

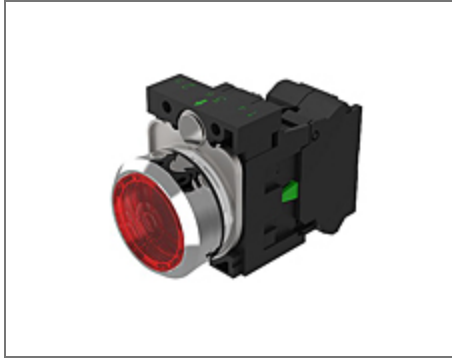

[Specifications](#) | [Bill of Materials](#)

### Specifications

Actuator	<a href="#">Illuminated pushbutton</a>
Lens Colour	Red, transparent
Function	2 Positions, momentary (O<l)
Housing Material	Metal/Plastic
Shape of Handle or Frontring	raised/ level to bezel
Lock System	None
Key	None
Key Type	None
Switching Angle	None
Contacts	1NC
Terminal	Spring-loaded terminal
Voltage Illumination	24V AC/DC

Mounting Type	Front mounting
Mounting Style	Holder
Environmental Rating	IP66, IP67, IP69K
Industry Standards/Certifications	UL, CSA, VDE, CCC, CE, RoHS
Switching Function	On-Off
Illumination	Red
Contact Material	Silver
Termination Style	Spring type
Mechanical Life	Maintain 500'000 switching cycles Momentary 3'000'000 switching cycles
AC Voltage	500 V
DC Voltage	500 V
Switching Current	10 A

## Bill of Materials

Actuator	45-2231.31E0.000
Holder	45-2300.1000.000
Switch Element 1	45-312.1Z40
LED Module	45-320.1E46