

HDC enclosures

HDC IP68 04A AWS 1M20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com



The new RockStar® enclosures are resistant to seawater and offer a high degree of shock resistance, meet IP 68 and IP 69K, and have been developed for use under extreme environmental conditions and designed for the high vibration requirements acc. to DIN EN 61373 cat. 2 (bogie). As such, this housing family is ideally suited for fault- and maintenance-free operation of heavy-duty connectors in transport and traffic engineering as well as in power engineering and in applications with extreme requirements. During development, measures were also implemented to make the enclosures extremely EMC-resistant.

General ordering data

Type	HDC IP68 04A AWS 1M20
Order No.	1081480000
Version	HDC enclosures, Size: 1, Protection degree: IP68, IP69K, Bulkhead enclosure, Screw plug, Standard, Size of cable entries: M 20
GTIN (EAN)	4032248844227
Qty.	1 pc(s).

**HDC enclosures
HDC IP68 04A AWS 1M20**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data**Dimensions and weights**

Length	50 mm	Length (inches)	1.969 inch
Width	67 mm	Width (inches)	2.638 inch
Height	43.7 mm	Height (inches)	1.72 inch
Mounting dimension - width	41 mm	Mounting dimension - height	41 mm
Net weight	135 g		

Temperatures

Limit temperature	-50 °C ... 125 °C
-------------------	-------------------

Dimensions

Cable entry	w. threading	Hole pitch length A2	41 mm
Total length housing	50 mm		

General data

EMC housings	Yes	Housing main material	diecast aluminium
Protection degree	IP68, IP69K	Surface finish	Powder coating

Version

Cable entry	w. threading	Clamp version	Screw plug
Design	Standard	Design of housing	Bulkhead enclosure
Design of locking system	Screw plug	Internal thread	M 20
Number of cable entry on top	0	Number of cable entry sideways	1
Sealing	Silicone rubber	Size	1
Size of cable entries	M 20	Suitable for ModuPlug®	No
Top part/bottom part/lid	lower part	Type	Bulkhead (Feed-Through)

Classifications

ETIM 3.0	EC000437	ETIM 4.0	EC000437
ETIM 5.0	EC000437	ETIM 6.0	EC000437
UNSPSC	30-21-18-01	eClass 5.1	27-14-34-19
eClass 6.2	27-14-34-19	eClass 7.1	27-44-05-15
eClass 8.1	27-44-05-15	eClass 9.0	27-44-05-15
eClass 9.1	27-44-02-02		

Approvals

Approvals



ROHS

Conform

Downloads

Brochure/Catalogue	CAT 3 HDC 17/18 EN FL FIELDWIRING EN
Engineering Data	EPLAN

Creation date June 7, 2018 10:48:13 AM CEST


Catalogue status 05.06.2018 / We reserve the right to make technical changes.

Data sheet

**HDC enclosures
HDC IP68 04A AWS 1M20**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

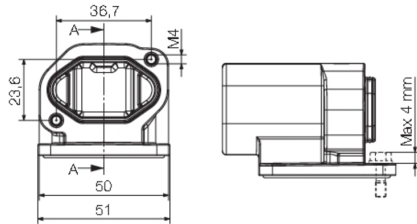

HDC enclosures
HDC IP68 04A AWS 1M20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories**IP68 O-ring seals**

We offer a variety of accessories, including seals, to accompany the housings.
 Because of the excellent sealing, you can achieve the best seal possible with our housings.
 Extensive testing has confirmed it – RockStar® remains impermeable to water to a depth of 50 metres This allows you to use heavy-duty connectors in environments which previously required fixed-wire installation.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
HDC DG 04A IP68	1987460000	Accessories, Enclosures accessories, Protection degree: Design of housing: Clamp version: Design: Approvals :	4050118379259	1 pc(s).

Flange seals

We offer a variety of accessories, including seals, to accompany the housings.
 Because of the excellent sealing, you can achieve the best seal possible with our housings.
 Extensive testing has confirmed it – RockStar® remains impermeable to water to a depth of 50 metres This allows you to use heavy-duty connectors in environments which previously required fixed-wire installation.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
HDC FLDG 04A AW IP68	1987470000	Accessories, Enclosures accessories, Protection degree: Design of housing: Clamp version: Design: Approvals :	4050118379204	1 pc(s).