


### Rocket 50



Look inside the back of a standard 4x12 and you may well find a quartet of Rocket 50s. This 12 inch guitar speaker performs well with any playing style, and won't break the bank.

#### 8 Frequency Response

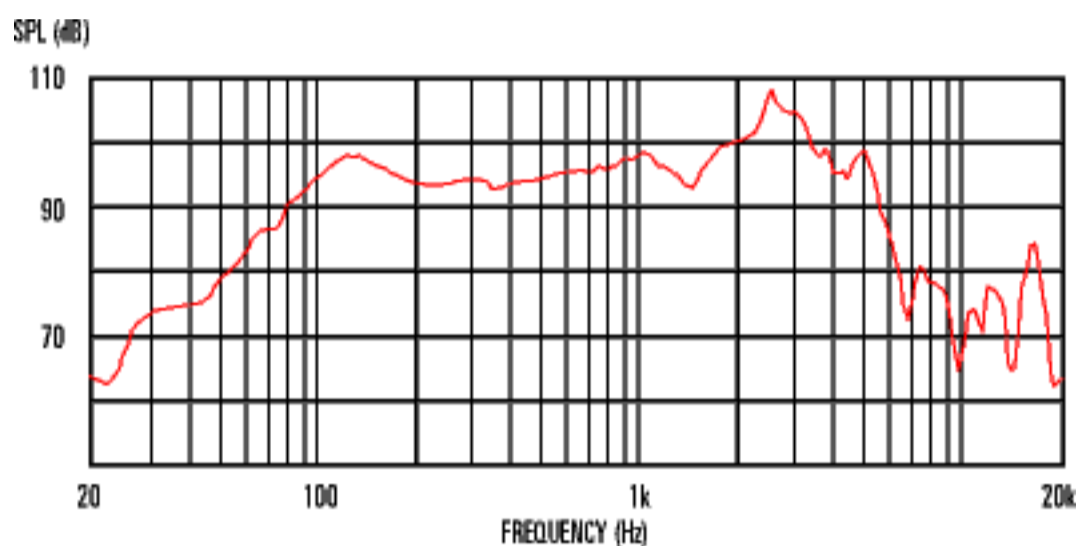

#### General Specifications

Nominal diameter	12", 305mm
Power rating	50Wrms
Nominal impedance	8
Sensitivity	95dB
Chassis type	Pressed steel
Voice coil diameter	1.5", 38.1mm
Voice coil material	Round copper
Magnet type	Ceramic
Magnet weight	17oz, 0.48kg
Frequency range	85-5000Hz
Resonance frequency, Fs	90Hz
DC resistance, Re	6.74

#### Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	3.9", 100mm
Mounting slot dimensions	0.31", 7.9mm &#216;
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	4.8", 122mm
Unit weight	4.4lb, 2.0kg