


EPA-2

Product Family: EPA

Ostby Barton: IP541

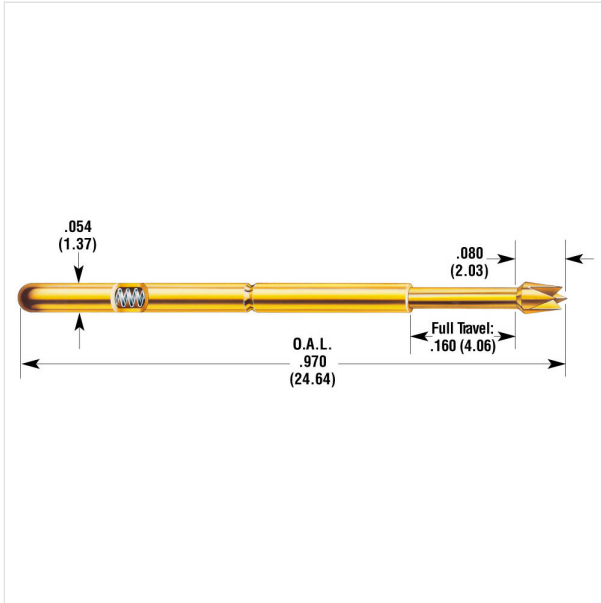

Mechanical:

Test Center (mil): 100

Test Center (mm): 2.54

Overall Length (mil): 970

Overall Length (mm): 24.64

Full Travel (mil): 160

Full Travel (mm): 4.06

Recommended Travel (mil): 107

Recommended Travel (mm): 2.72

Mechanical Life (no of cycles): 2,000,000

Thermal:

Max Operating Temp (°C): 105

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 5

Average Probe Resistance (mOhm): 35

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 1.08 (31.00) - 3.50 (99.00) - Music Wire, Silver plated

Alternate - 2.64 (75.00) - 6.50 (184.00) - Music Wire, Silver plated

Ultra High - 4.09 (116.00) - 10.00 (283.00) - Music Wire, Silver plated

Body Type

Straight

Pylon Bend

Materials & Finishes:

Plunger Material: Heat-treated BeCu, Gold plated over hard Nickel


Barrel Material: Work-hardened Nickel Silver, Gold plated over hard Nickel

TIPS:


Tip Materials: BeCu

Tips:


EPA-2A

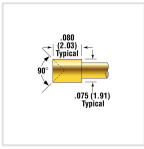


EPA-2B30

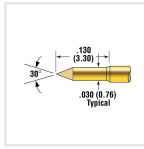


EPA-2B40

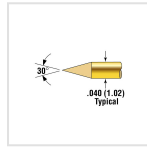


EPA-2C30

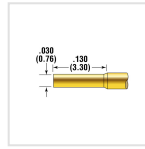


EPA-2C40

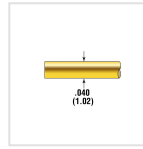


EPA-2D

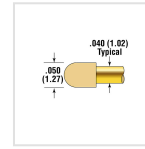


EPA-2E

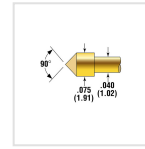


EPA-2F

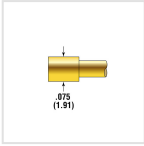


EPA-2G30

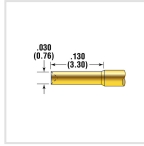


EPA-2G40

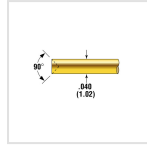


EPA-2H

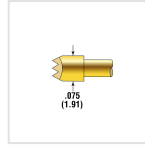


EPA-2J30

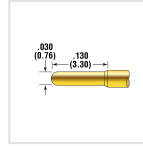


EPA-2J40

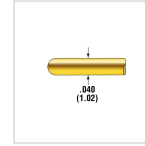


EPA-2L

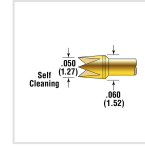


EPA-2P

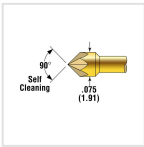

EPA-2T

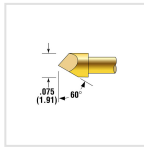


EPA-2X

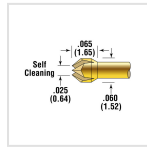


Related Products:


SPR-2W

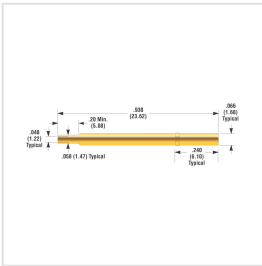


SPR-2W-1

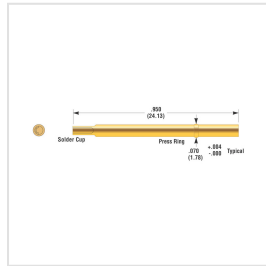

SPR-2W-2

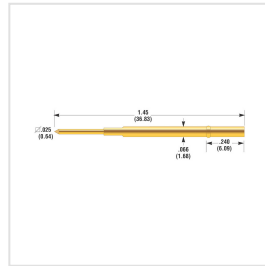

SPR-2W-3

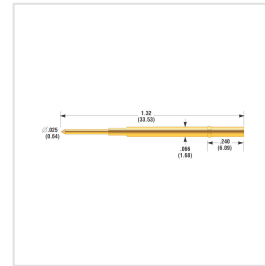

SPR-2Y

