

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200710070](#)
Status: **Active**
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change (M12) Single Keyway with PG9 Cable Fitting, 90° Angle Female, 5 Poles, Cable Diameter 4.10-8.10mm

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Field Attachable / Accessories
 Series [120071](#)
 Approvals cCSAus certified
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad Micro-Change \(M12\) Connectors](#)
 Product Name Micro-Change (M12)
 Type Field Attachable Connector
 UPC 78172501129

Physical

Cable Diameter 4.10 - 8.10mm (.161-.319")
 Coupling Type Internal Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Female
 Keyway Single
 Material - Connector Body PA
 Material - Coupling Nut Nickel-plated Brass
 Material - Plating Mating Silver
 Net Weight 45.359g
 Orientation 90° Angle
 Poles 5
 Temperature Range - Operating -25°C to +90°C
 Wire Size AWG 18

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 30V AC / 36V DC

Material Info

Engineering Number 8A5001-32

Reference - Drawing Numbers

Sales Drawing SD-120071-013

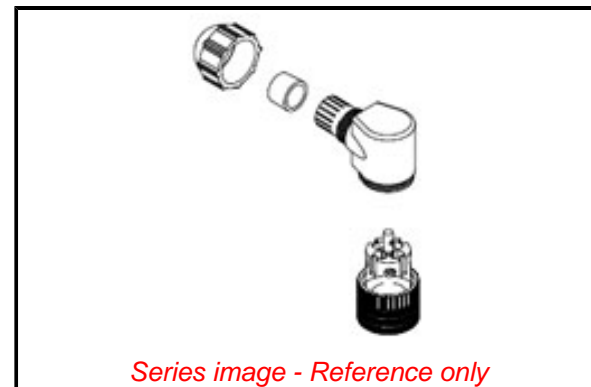

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | 50 Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[120071](#) Series