
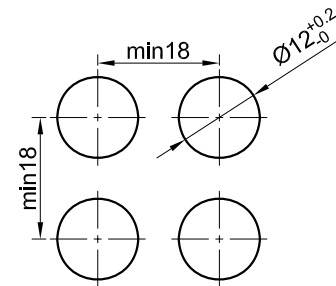


AB-AV-1212 IP67 24V GREEN INDICATOR


SWITCHES

Specifications

AB-AV-1212	
Terminal type	Solder terminals 1.8x 0.4mm
LED	24V Green
Rated current	2-15mA
Panel cut out	12mm
LED life	About 40,000 hours
Dielectric strength	2000V AC 50Hz 5 seconds
Operating temperature	-25°C~+55°C
Torque	0.3Nm max. applied to nut
IP degree	IP67
Material:	
Lamp Shade	Epoxy resin
Body	Stainless steel
Base	PA

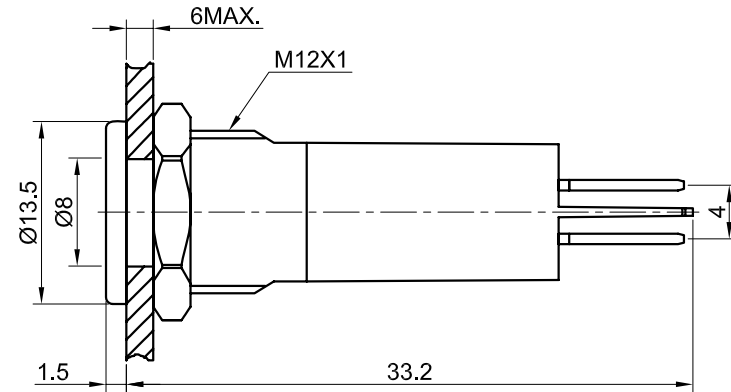

PANEL CUTOUT
MAX.PANEL THICKNESS
6mm

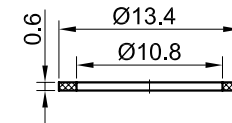

Seal Ring

ROHS Compliant

DIMENSIONS	TOLERANCE
0.00 TO 30.00mm	±0.20mm
30.01 TO 80.00mm	±0.25mm
80.01 TO 150.00mm	±0.30mm
150.01 ↑	±0.40mm



ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

www.abcomponents.co.uk