


- Notes:
- 1. Pitch: 2.54mm
  - 2.4 Terminal Strips: 2520 Tie-point
  - 3.7 Distribution Strip: 700 Tie-point
  - 4. Rated voltage/current: 300V / 3-5A
  - 5. Insulation resistance: 500MΩ/DC500V
  - 6. Withstanding voltage: AC1000V/1Min
  - 7. Wire range: 29~20 AWG
  - 8. Temp. Range: -25°C~+80°C
  - Strip length: 7-8mm
  - 9. Undimensioned Tolerances:

Packing: skin packing

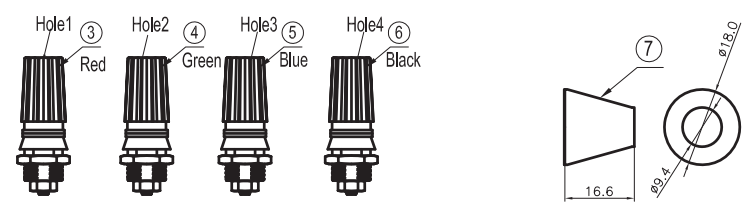

TOLERANCES EXCEPT AS NOTED

variable range	linear dimension				fillet	chamfer		∠short angle sid				≡	-	□	//	⊥	
	to 6	over 6 to 30	over 30 to 120	over 120 to 480		to 6	over 6 to 10	to 10	to 10	to 50	to 120						to 120
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1'	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

MATERIAL:		<b>GOLDSUN ELECTRONICS CO., LTD.</b>			
DRAWN: nomo		ITEM NO. 26W6052	MFG NO. EPB-108		
VERIFY PEOPLE: Chesley		Description SOLDERLESS BREADBOARD 4 STRIPS 7 DISTRIBUTION, 4 BINDING POSTS			Rev. 1
UNIT: mm	SCALE:	SHEET 1 OF 1	CAS No: ERN No:		