
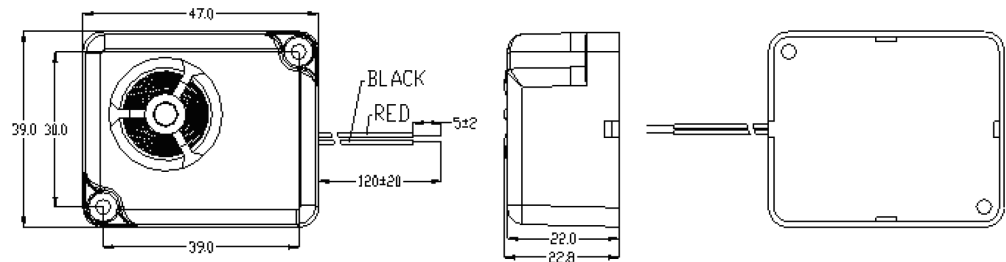


Panel Mount - Wire Lead Type

RoHS
Compliant

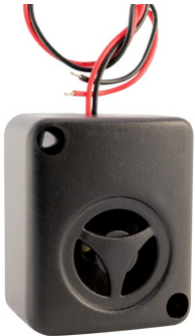

Dimensions : Millimetres
Tolerance: ±0.5mm

Specifications

Part Number	ABI-053-RC
Rated Voltage	12V DC
Operating Voltage	6 ~ 14V DC
Rated Current	≤ 70mA (50mA Typ.)
Sound Output level	≥ 102dB @30cm
Resonant Frequency	2000Hz- 3500Hz
Tone	Siren - Dual Tone
Housing Material	Black ABS
Operating Temperature	-10°C to +60°C
Storage Temperature	-40°C to +80°C
Lead Wire	UL1007 AWG26
Lead Length	120mm
Weight	27g

Important Notice : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. pro-SIGNAL is the registered trademark of the Group. © Premier Farnell Limited 2016.