

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190990028](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Snap Spade for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Blue

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19099](#)
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Solderless Terminals](#)
 Product Name InsulKrimp
 Type Spade Snap
 UPC 800753089105

Physical

Barrel Type Closed
 Color - Resin Blue
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 0.718/g
 Packaging Type Adhesive Tape on Reel
 Stud Size 5-6 (M3-3.5)
 Wire Insulation Diameter 4.40mm max.
 Wire Size AWG 14, 16

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number BB-2707-06XT

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001,
 PS-19902-015-001
 Sales Drawing BBCD20502

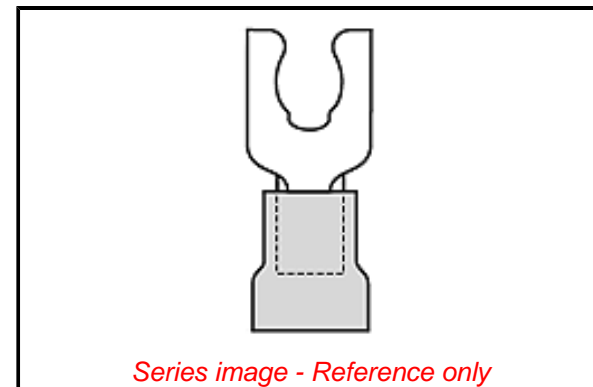

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Contained Per
 -ED/01/2018 (15
 January 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Prop65

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Missing Compliance
 Data

Not Contained

Search Parts in this Series

[19099 Series](#)