

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0039000338](#)
Status: **Active**
Overview: Standard .062" Pin and Socket Power Connectors
Description: 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Series 1855, 3.68mm Pitch, Female, Tin (Sn) Plated Brass Contact, 22-28 AWG, Reel

Documents:

| | |
|---|---|
| Drawing (PDF) | Product Specification PS-1855-003 (PDF) |
| Product Specification PS-1855-002 (PDF) | RoHS Certificate of Compliance (PDF) |

General

| | |
|-------------------------|---|
| Product Family | Crimp Terminals |
| Series | <u>1855</u> |
| Application | Power, Wire-to-Wire |
| Crimp Quality Equipment | Yes |
| Overview | <u>Standard .062" Pin and Socket Power Connectors</u> |
| Packaging Alternative | <u>39-00-0339 (Loose)</u> |
| Product Name | Standard .062" |
| UPC | 800753332874 |

Physical


| | |
|--------------------------------|----------------------|
| Gender | Female |
| Material - Metal | Brass |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Net Weight | 165.300/mg |
| Packaging Type | Reel |
| Plating min - Mating | 0.889µm |
| Plating min - Termination | 0.889µm |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 1.10-1.50mm |
| Wire Size AWG | 22, 24, 26, 28 |
| Wire Size mm ² | N/A |

Material Info

| | |
|--------------------|-------|
| Engineering Number | 1855T |
|--------------------|-------|

Reference - Drawing Numbers

| | |
|-----------------------|--------------------------|
| Product Specification | PS-1855-002, PS-1855-003 |
| Sales Drawing | SD-1855* |

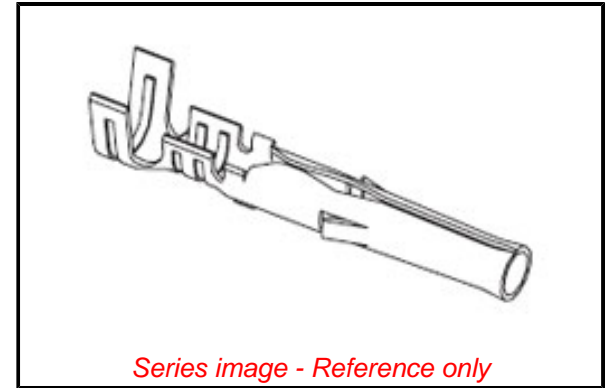

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[1855 Series](#)

Use With

[1625 Receptacle Housing](#)