

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511120310](#)
Status: **Active**
Description: 2.50mm Pitch Wire-to-Wire Plug Housing, with Optional Panel Mount, 3 Circuits

Documents:

[3D Model](#) [Packaging Specification SPK-51112-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-51111-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [51112](#)
 Application Signal, Wire-to-Wire
 Product Name N/A
 UPC 800755527612


Physical

Circuits (maximum) 3
 Color - Resin Natural
 Flammability 94V-0
 Gender Plug
 Glow-Wire Capable No
 Material - Resin Polyester
 Net Weight 1068.400/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.50mm
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification SPK-51112-001-001
 Product Specification PS-51111-001
 Sales Drawing SD-51112-**10

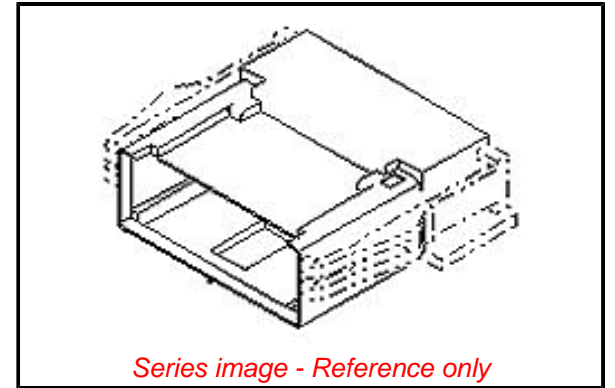

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/01/2018 (15
 January 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[51112](#) Series

Mates With

[51111](#) , [51111](#) With Retainer

Use With

[50398](#)