

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0533981571](#)  
**Status:** **Active**  
**Overview:** [PicoBlade Connector System](#)  
**Description:** 1.25mm Pitch PicoBlade Header, Surface Mount, Vertical, 15 Circuits

**Documents:**

[3D Model](#) [Packaging Specification SPK-53398-002-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-51021-024-001 \(PDF\)](#)

**Agency Certification**

UL E29179

**General**

Product Family PCB Headers  
 Series [53398](#)  
 Application Signal, Wire-to-Board  
 Current Derating Order No 987651-3691  
 Overview [PicoBlade Connector System](#)  
 Product Name PicoBlade  
 UPC 822348164424


**Physical**

Breakaway No  
 Circuits (Loaded) 15  
 Circuits (maximum) 15  
 Color - Resin Natural  
 Durability (mating cycles max) 30  
 First Mate / Last Break No  
 Flammability 94V-0  
 Glow-Wire Capable No  
 Guide to Mating Part No  
 Lock to Mating Part Yes  
 Mated Height 5.70mm  
 Material - Metal Phosphor Bronze  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Material - Resin Nylon  
 Net Weight 415.800/mg  
 Number of Rows 1  
 Orientation Vertical  
 PC Tail Length 0.60mm  
 PCB Locator No  
 PCB Retention Yes  
 Packaging Type Embossed Tape on Reel  
 Pitch - Mating Interface 1.25mm  
 Polarized to Mating Part Yes  
 Polarized to PCB Yes  
 Shrouded Partial  
 Stackable No  
 Temperature Range - Operating -40° to +85°C  
 Termination Interface: Style Surface Mount

**Electrical**

Current - Maximum per Contact 1.0A  
 Voltage - Maximum 125V

**Material Info**

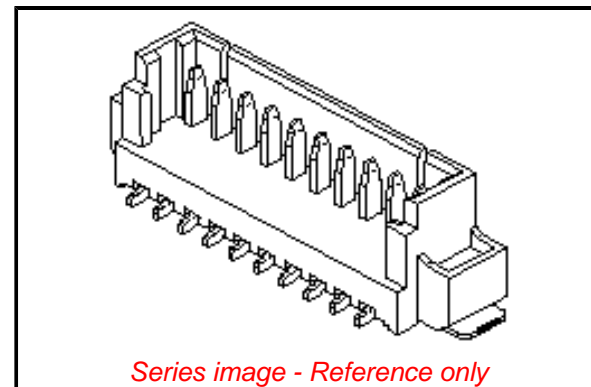

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
 ED/61/2018 (27 June  
 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[53398 Series](#)

**Mates With**

[51021](#) PicoBlade Wire-to-Wire and Wire-to-Board Housing

**Reference - Drawing Numbers**

Packaging Specification

Product Specification

Sales Drawing

SPK-53398-002-001

PS-51021-024-001

SD-53398-032, SD-53398-033-001

This document was generated on 10/19/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**