

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0536270774](#)
Status: **Active**
Overview: SlimStack™ 0.635mm Pitch Board-to-Board Connectors
Description: 0.635mm Pitch SlimStack Header, Surface Mount, Dual Row, Vertical Stacking, 10.00 and 16.00mm Stacking Heights, 70 Circuits, with Embossed Tape with Cover Packaging

Documents:

[3D Model](#) [Packaging Specification SPK-53627-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification 527600000-000 \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family PCB Headers
 Series [53627](#)
 Application Board-to-Board, Signal
 Comments Stacking-Type
 Overview [SlimStack™ 0.635mm Pitch Board-to-Board Connectors](#)
 Product Name SlimStack
 UPC 822348165544


Physical

Breakaway No
 Circuits (Loaded) 70
 Circuits (maximum) 70
 Color - Resin Brown
 Durability (mating cycles max) 50
 First Mate / Last Break No
 Glow-Wire Capable No
 Guide to Mating Part No
 Keying to Mating Part None
 Lock to Mating Part Yes
 Mated Height 10.00mm, 16.00mm
 Mated Width 6.40mm
 Material - Metal Copper Alloy
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Net Weight 1216.261/mg
 Number of Rows 2
 Orientation Vertical
 PCB Locator Yes
 PCB Retention Yes
 Packaging Type Embossed Tape on Reel
 Pitch - Mating Interface 0.64mm
 Polarized to PCB Yes
 Robotic Placement Metal Cap
 Shrouded Fully
 Temperature Range - Operating -55° to +105°C
 Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 0.5A
 Voltage - Maximum 100V

Material Info

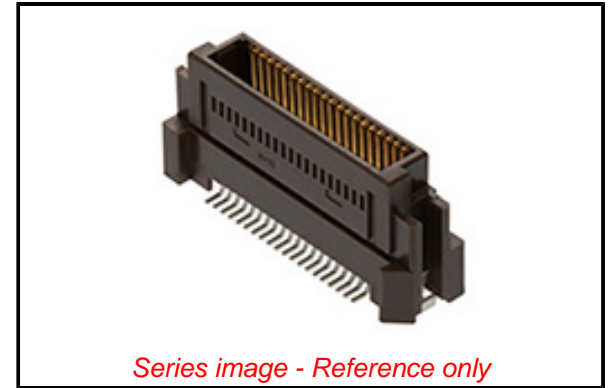

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[53627 Series](#)

Mates With

SlimStack Receptacle [52885](#) , [52901](#)

Reference - Drawing Numbers

Packaging Specification

Product Specification

Sales Drawing

SPK-53627-001-001

527600000-000

SD-53627-001-001, SD-53627-002-001

This document was generated on 10/26/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION