


KEMET, SSHB10H, Commercial Grade, 0.0194 H

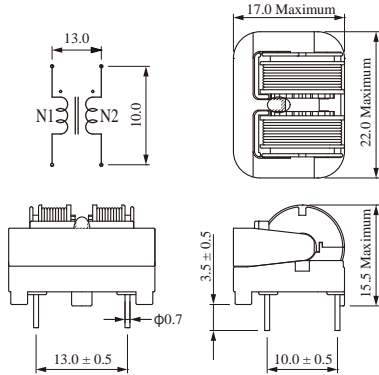

General Information	
Series:	SSHB10H
Style:	Through-Hole Choke
Description:	Common Mode Filter, SS Coils, SSHB10H, High Impedance Type
RoHS:	Yes
Miscellaneous:	Temperature Rise Maximum: 50 K
Notes:	Marking: R08 Lot No.

Dimensions	
L	22mm MAX
T	17mm MAX
H	15.5mm MAX
S	10mm +/-0.5mm
S1	13mm NOM
LL	3.5mm +/-0.5mm
F	0.7mm NOM

Specifications	
Inductance:	19.4 mH (10 kHz)
Temperature Range:	-25/+120C
Rated Temperature:	120C
Current:	0.8 Amps
Voltage AC:	250 VAC
Withstanding Voltage:	2400 VAC MAX
Insulation Resistance:	100 MOhms

Packaging Specifications	
Weight:	10 g
Packaging:	Tray
Packaging Quantity:	300