


KEMET, SN, AC Line Filters, Normal Mode, 92 uH, MIN

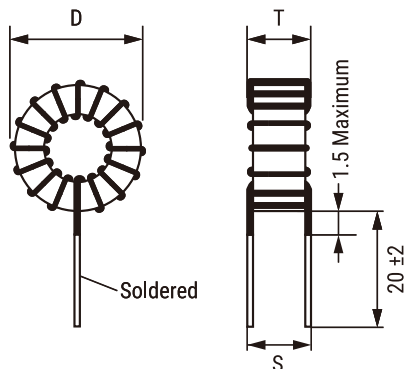

Dimensions	
D	30mm MAX
T	18mm MAX
LL	20mm +/-2mm
S	16mm NOM

Packaging Specifications	
Packaging:	Tray
Packaging Quantity:	250
Weight:	35.1 g

General Information	
Series:	SN
Style:	Through-Hole
Features:	Compact Size
RoHS:	Yes
Miscellaneous:	33 (K) Temperature Rise Max.

Specifications	
Inductance:	92 uH (0.1 MHz)
Inductance Tolerance:	MIN
Temperature Range:	-25/+105C
DC Resistance:	30 mOhms