

REV. 1


DCO 170398

COIL: @ 25°C	
RESISTANCE	2500 OHMS ± 10%
NOMINAL VOLTAGE	8.0 mADC
MUST OPERATE	4.0 mADC
MUST RELEASE	2.0 mADC MAX, 0.4 mADC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 ± 1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE 15 MS MAX
	RELEASE 10 MS MAX
	CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

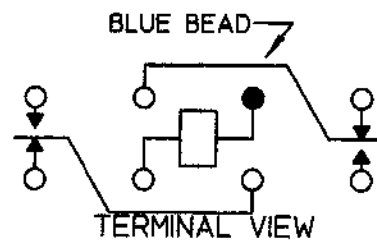

CONTACT RATING: LOW LEVEL TO
2 AMPS @ 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 2/06/01

CK. 02-07-01

CII Technologies™
advanced control electronic solutions

CUST. QPL
CUST. NO. M5757/13-120 REV. _____

3SAT RELAY

3SAT1337A2