




ARCA AR IPW

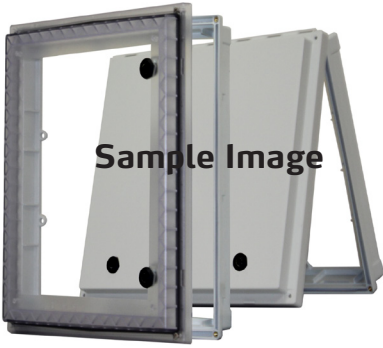

Order Symbol: AR IPW 1210 KF

Description: Key Cylinder Lock Opaque Flat Cover

Remarks

Includes, cover and base with formed in place PUR gasket, mounting hardware and template for mounting frame

Dimensions	Length (metric)	Width inches (metric)	Height inches (metric)	Rating:
Inner Dimensions	11.42 (289.99)	9.49 (241.0)	2.31 (58.67)	NEMA 4, 4X,12 & 13
Outer Dimensions	13.46 (341.84)	11.62 (295.08)	2.45 (62.23)	

Materials

- Material: Polycarbonate
- Base Color: RAL 7035 - LIGHT GRAY
- Cover Color: RAL 7035 - LIGHT GRAY
- Gasket material: Polyurethane

Temperature

- Temperature C° (short term): -40° - 120° C"
- Temperature C° (continuous): -40° - 80° C"
- Temperature F° (short term): -40° - 250° F
- Temperature F° (continuous): -40° - 175° F

