



XPLOR
PH15 Headlamp
Instruction Manual



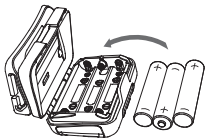

2a-2b

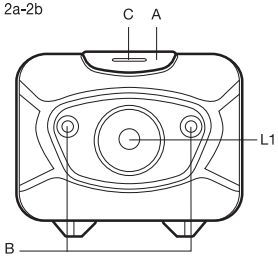

Getting to know your headlamp

- (A) Main button
- (B) Motion sensors
- (C) Sensor indicator light (red light)
- (L1) Main light

1. Fitting batteries

- 1a. Check the headlamp is off before opening battery compartment.
- 1b. Remove old batteries and insert new batteries following the polarity markings (+) and (-) on the battery compartment.
- 1c. Close battery compartment.

2. Operation

2a. Main light - Cool white (L1)

Short press (A) to cycle through light modes	Main light on: High → Medium → Low → Flashing → Off
When (L1) is on, long press (A) for 2 second	Motion sensor activated and (C) is on (L1 flashes once)
When motion sensor mode is activated, wave hand ~5cm in front (B) to cycle through light modes	Main light on: High → Mid → Low
When motion sensor mode is activated, short press (A)	Motion sensor deactivated and (C) is off

2b. Other operations

When (L1) is off, long press (A) for > 5 seconds	Lock mode activated (L1 flashes twice) In lock mode, (L1) flashes momentarily when (A) is pressed.
When lock mode activated, long press (A) for > 5 seconds	Lock mode deactivated (L1 flashes twice)

3. Specifications

Lumen	300 lm – 5 lm	Impact resistance	1.0 m
Candela	Max. 6200 cd	Battery	Alkaline/NiMH (3 x AAA)
Beam distance	Max. 157 m	LED	Cree
Runtime	5 h – 69 h	Weight	110g (with batteries)
P rating	IPX6	Dimensions	46 x 56 x 34 mm