


# ROLINE UTP Cable Cat.6 Component Level, LSOH, grey, 5.0 m

<b>Product No.</b>	21.15.2505
<b>Manufacturer</b>	ROLINE
<b>Manufacturer No.</b>	21.15.2505
<b>EAN (single piece)</b>	7611990167449

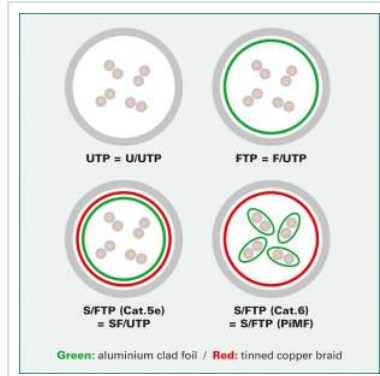

Patch cable for networking connections between devices. Prepared unshielded Twisted Pair cable with RJ-45 connectors on both ends. Durable due to moulded kink protection. Flexible cable, suitable for narrow bending. High quality plugs with gold plated contacts. Contact settings 1:1, in accordance with the EIA/TIA 568 standard. Construction: 4-pair stranded copper wire. Halogen-free, flame retardant, low smoke.

## 100 % Component level testing

- GHMT Certificate No. z4423b-16-E

## Technical specifications

Manufacturer	ROLINE
Product group	Twisted Pair Cable
Product type	UTP Patch Cables
Colour	grey
Length	5 m

Shield type	UTP
Transfer quality	Cat6 / Class E
Component-Level certified	Yes
Impedance	100 Ohm
Quantity of wires	8
Conductor type	Wire
Crossed	No
Colour (Spout)	grey
Cable LSOH	Yes
Side 1 Connector Type	RJ-45
Side 1 Connector Gender	Male
Side 2 Connector Type	RJ-45
Side 2 Connector Gender	Male
Connector Type RJ45	Standard