

## PS12\_SCMS\_0000\_O309E\_XX.X\_M0

### Description

12 pigtail set, SC-HQ BTW, MM, fiber 0.9mm\_XX.X\_fiber colour EN / IEC, OM3 BendOptimized



Features	Features
- Push-pull connector	
- One-piece design for easy and quick termination	
- High mechanical and thermal resistance according to Telcordia GR-326-CORE	

### Technical Data

#### General Data

Description	Values
General Typ	SC pigtail
Operation temperature	-40 up to 85°C
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

#### Connector left


Description	Values
Connector typ	SC pigtail
Polish	UPC
Color Housing	Black
Color Boot	Aqua
Design connector acc. To	IEC 61754-4, TIA 604-3
Performance class H+S	0
Return Loss	>35dB
Durability	1000

#### Cable

Description	Values
Cable typ	Semi-tight Tube
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	G50/125-OM3 BendOptimized

PS12\_SCMS\_0000\_O309E\_XX.X\_M0

## Technical Drawing

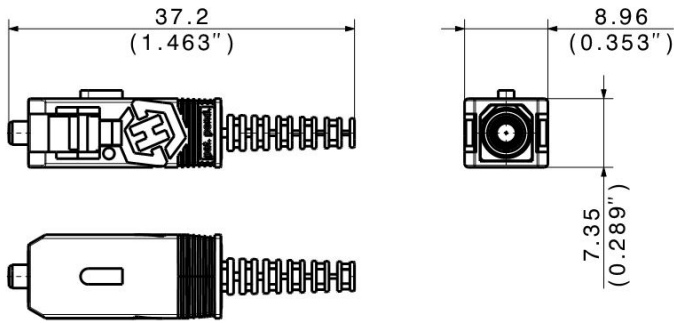

## Ordering information

Meter (m)	Item number	Description
-----------	-------------	-------------