

PS12_SCMS_0000_O409E_XX.X_M0

Description

12 pigtail set, SC-HQ BTW, MM, fiber 0.9mm_XX.X_fiber colour EN / IEC, OM4 BendOptimized



Features	Features
- Push-pull connector	
- One-piece design for easy and quick termination	
- High mechanical and thermal resistance according to Telcordia GR-326-CORE	

Technical Data

General Data

Description	Values
General Typ	SC pigtail
Operation temperature	up to °C
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes


Connector left

Description	Values
Connector typ	SC pigtail
Polish	UPC
Color Housing	Black
Color Boot	Heather violet
Design connector acc. To	IEC 61754-4, TIA 604-3
Performance class H+S	0
Return Loss	>35dB
Durability	1000

Cable

Description	Values
Cable typ	Semi-tight Tube
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	G50/125-OM4 BendOptimized

Technical Drawing

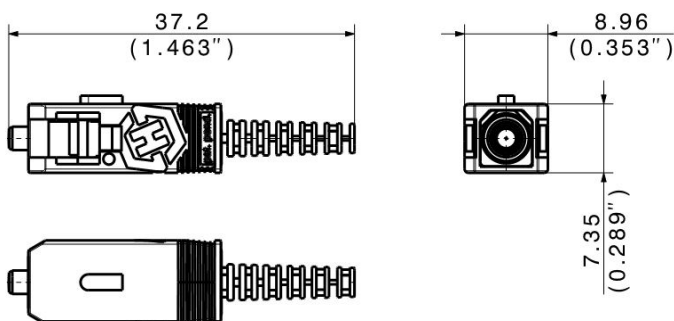

PS12_SCMS_0000_O409E_XX.X_M0

Ordering information

Meter (m)	Item number	Description
-----------	-------------	-------------