

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191310002**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp Block Spade Tongue Terminal for 10 to 12 AWG Wire, Stud Size 10 (M5), Length 27.31mm

Documents:

Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
Product Specification 194130096-000 (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	<u>19131</u>
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<u>Solderless Terminals</u>
Product Name	InsulKrimp
Type	Spade Block
UPC	800753101258

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.782/g
Packaging Type	Bag
Stud Size	10 (M5)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12
Wire Size mm ²	3.30-5.00

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	C-2105-10X
--------------------	------------

Reference - Drawing Numbers

Product Specification	194130096-000, PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	CCD20301

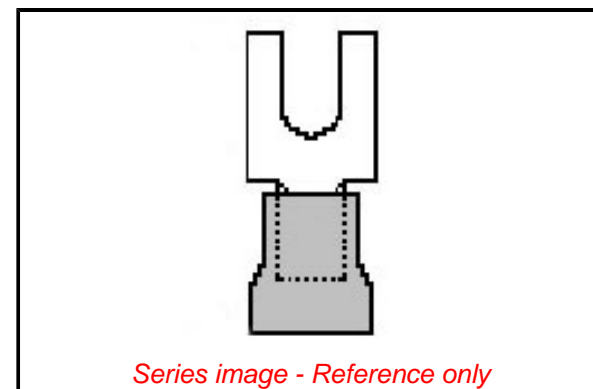

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Contained Per - ED/88/2018 (15 January 2019)
Di-(2-ethylhexyl)phthalate (DEHP)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19131 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool	<u>640010100</u>
Hand Crimp Tool	<u>640010300</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050300</u>

This document was generated on 03/25/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION