

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191790019**
Status: **Active**
Description: HOOK INSULKRIMP (C-211-10X)

Documents:

Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)	

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	<u>19179</u>
Crimp Quality Equipment	Yes
UPC	800753035898

Physical


Flammability	94V-0
Net Weight	1.707/g

Material Info

Engineering Number	C-211-10X
--------------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
-----------------------	---

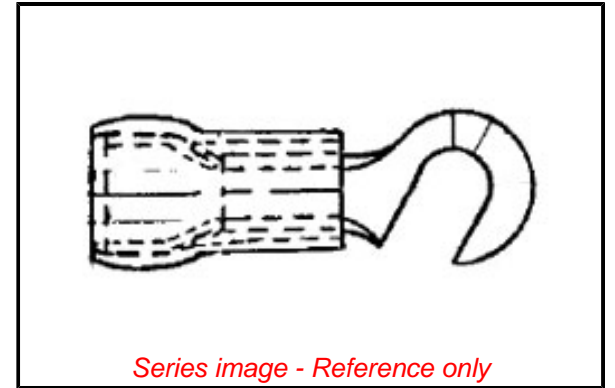

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Contained Per -
ED/88/2018 (15
January 2019)
Di-(2-
ethylhexyl)phthalate
(DEHP)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19179 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand	<u>640010100</u>
Crimp Tool	
Hand Crimp Tool	<u>640010300</u>
Crimp Head for the	<u>640050100</u>
AT-200 Pneumatic	
Hand Tool	
Crimp Head for the	<u>640050300</u>
AT-200 Pneumatic	
Hand Tool	

This document was generated on 03/25/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION