


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511910200](#)
Status: **Active**
Overview: Mini-Latch Wire-to-Board / Wire-to-Wire Connector System
Description: 2.50mm Pitch Mini-Latch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Guide Rails, 2 Circuits

Documents:

3D Model	Product Specification PS-51191-003 (PDF)
Drawing (PDF)	Application Specification 511910000-AS-000 (PDF)
Product Specification 2055050000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-51191-002 (PDF)	

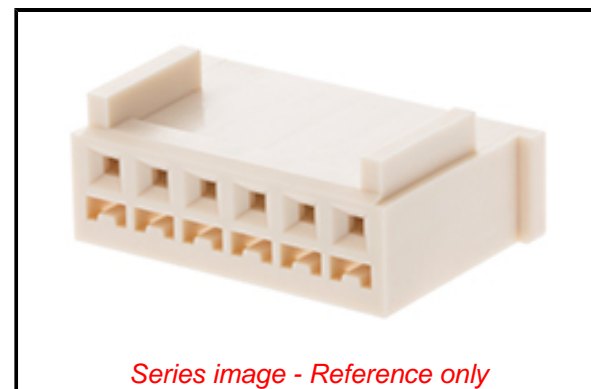

Series image - Reference only

Agency Certification

UL E29179

General

Product Family	Crimp Housings
Series	51191
Application	Signal, Wire-to-Board, Wire-to-Wire
Overview	<u>Mini-Latch Wire-to-Board / Wire-to-Wire Connector System</u>
Product Name	Mini-Latch
UPC	800753327702

Physical

Circuits (maximum)	2
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	276.600/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	511910000-AS-000
Product Specification	2055050000-PS-000, PS-51191-002, PS-51191-003
Sales Drawing	SD-51191-004

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[51191](#) Series

Mates With

[5045](#) Vertical Header . [5046](#) Right Angle Header . [5240](#) Plug Housing

Use With

[50802](#) Crimp Terminal