

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0350230006](#)  
**Status:** **Active**  
**Description:** 2.00mm Pitch Board-in Housing, Right-Angle, 6 Circuits, Natural

**Documents:**

[3D Model](#) [Packaging Specification PK-35023-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-35023-001-001 \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [35023](#)  
 Application Signal  
 Product Name Board-in  
 UPC 800754255271

**Physical**

Circuits (maximum) 6  
 Color - Resin Natural  
 Flammability 94V-0  
 Gender Receptacle  
 Glow-Wire Capable No  
 Material - Resin Nylon  
 Net Weight 0.102/g  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 2.00mm  
 Stackable No  
 Temperature Range - Operating -40° to +105°C


**Solder Process Data**

Lead-freeProcess Capability N/A

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-35023-001-001  
 Product Specification PS-35023-001-001  
 Sales Drawing SD-35023-001

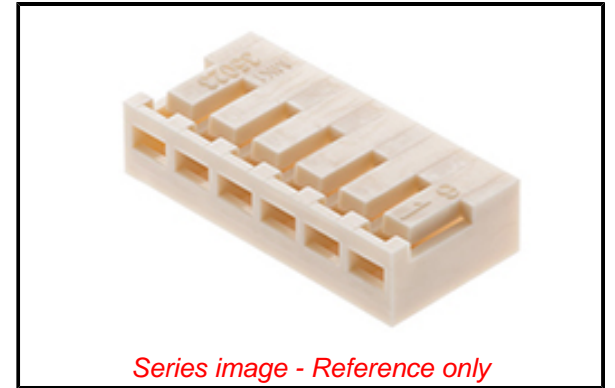

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/88/2018 (15  
 January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[35023 Series](#)

**Use With**

Straight Terminal [350449102](#) , [350449260](#)

<br>Right Angle Terminal [350211201](#) ,

[350211301](#) , [350211360](#)