

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0194300003**
Status: **Active**
Overview: Splices
Description: See and Splice 4 Circuit Push-in Wire Connector for 12-22 AWG Wire

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E32244

General

Product Family Splices
 Series 19430
 Comments Yellow Insert|1000V max. for lighting/sign fixtures,
 Yellow Insert|1000V max. for lighting/sign fixtures
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Splices
 Product Name See and Splice
 UPC 822348218905

Physical

Barrel Type Closed
 Color - Resin Yellow
 Flammability 94V-2
 Insulation None
 Material - Metal Brass
 Material - Plating Mating N/A
 Net Weight 2.881/g
 Packaging Type Bag
 Temperature Range - Operating -30° to +105°C
 Wire Insulation Diameter 3.30mm is the nominal O.D.
 Wire Size AWG 12, 14, 16, 18, 20, 22

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number PC4-YELLOW

Reference - Drawing Numbers

Sales Drawing SD-19430-001

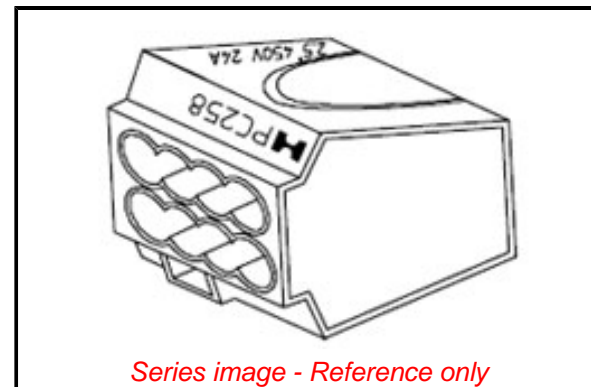

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per
 -ED/01/2018 (15
 January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19430 Series