

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191930072](#)  
**Status:** **Active**  
**Overview:** [VersaKrimp Terminals and Splices](#)  
**Description:** VersaKrimp Ring Tongue Terminal for 14-16 AWG Wire

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19193](#)  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview [VersaKrimp Terminals and Splices](#)  
 Product Name VersaKrimp  
 Type Ring  
 UPC 800755049176

**Physical**


Barrel Type Closed - Brazed  
 Insulation None  
 Material - Plating Mating Tin  
 Net Weight 0.934/g  
 Packaging Type Bag  
 Stud Size 1/4" (M6)  
 Wire Size AWG 14, 16  
 Wire Size mm<sup>2</sup> 1.30-2.00

**Material Info**

Engineering Number BB-325-14

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing BBCD30101

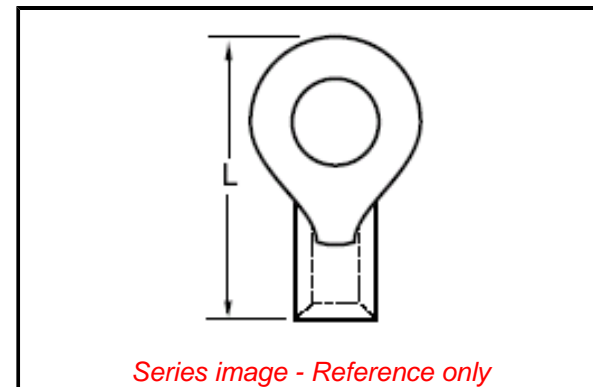

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per  
 -ED/88/2018 (15  
 January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[19193 Series](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

| Description                                   | Product #                 |
|---|---------------------------|
| PremiumGrade Hand Crimp Tool                  | <a href="#">640030100</a> |
| Crimp Head for the AT-200 Pneumatic Hand Tool | <a href="#">640070100</a> |

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**