

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190220022](#)
Status: **Active**
Overview: Standard Quick-Disconnect Terminals
Description: Krimptite Quick Disconnect, Male, for 14-16 (2.00-1.30mm²) Wire, Box, Tab 4.75 x 0.51mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-005-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

General

Product Family	Quick Disconnects
Series	19022
Comments	Economical, Economical
Crimp Quality Equipment	Yes
Insulated	No
Overview	Standard Quick-Disconnect Terminals
Product Name	Krimptite
Type	Quick Disconnect
UPC	800755050189

Physical

Barrel Type	Closed
Gender	Male
Glow-Wire Capable	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Zinc Chromate
Material - Plating Termination	Zinc Chromate
Net Weight	0.472/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	5.080µm
Plating min - Termination	5.080µm
Polarized to Mating Part	No
Tab Thickness	0.51mm
Tab Width	4.75mm
Temperature Range - Operating	Per Wire Specification
Wire Size AWG	14, 16
Wire Size mm ²	1.30-2.00

Electrical


Voltage - Maximum	Per Wire Specification
-------------------	------------------------

Material Info

Engineering Number	MCT-17
--------------------	--------

Reference - Drawing Numbers

Product Specification	PS-19902-005-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19022-007

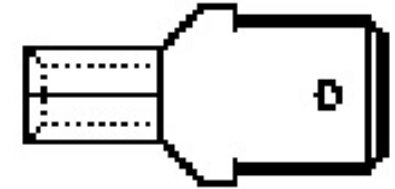

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19022 Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	640031200
Crimp Head for the AT-200 Pneumatic Hand Tool	640071200