



Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAC
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With front plate 45 x 45 mm
Type of operator	Key Ronis 8R1
Rotary handle padlocking	Without
Presentation of legend	With mat black legend
Switching angle	60 °

Complementary

Mechanical durability	1000000 cycles
CAD overall width	45 mm
CAD overall height	45 mm
CAD overall depth	69 mm
Product weight	0.063 kg

Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to IEC 529 IP65 conforming to NF C 20-010

Contractual warranty

Warranty period	18 months
-----------------	-----------

Operating Head

For Ø 22 mm/0.87 in. Hole, Front Mounting Body

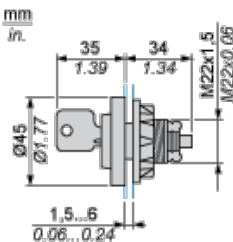

Operating Head

Panel Cut-out

