

## KBD1S

operating head 60 x 60 mm - metallic color - key - blank for engraving



### Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KBD
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With front plate 60 x 60 mm
Type of operator	Key Ronis 8R1
Rotary handle padlocking	Without
Presentation of legend	With metallic legend
Switching angle	45 ° 90 °

### Complementary

Mechanical durability	1000000 cycles
CAD overall width	60 mm
CAD overall height	60 mm
CAD overall depth	69 mm
Product weight	0.068 kg

### Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to IEC 529 IP65 conforming to NF C 20-010

### Contractual warranty

Warranty period	18 months
-----------------	-----------

### Operating Head

For Ø 22 mm/0.87 in. Hole, Front Mounting Body

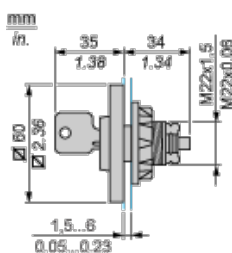

### Operating Head

Panel Cut-out

