


DESOLDERING BRAIDS

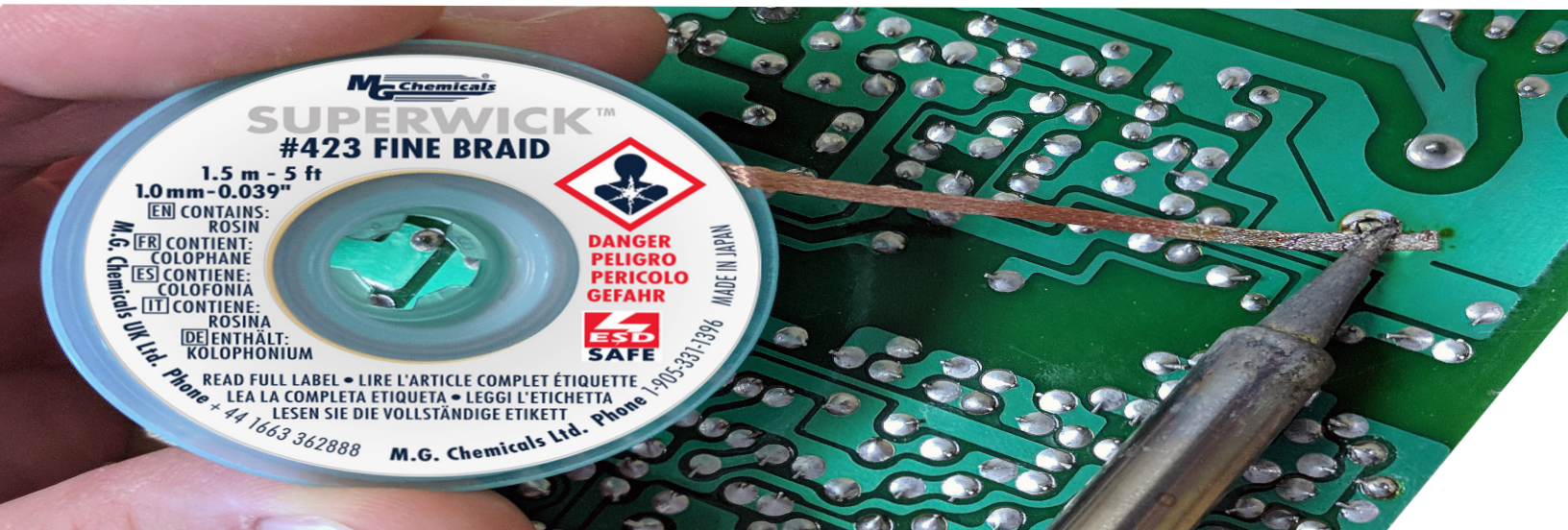

Fast and easy removal of all solder types

Features and Benefits:

- High purity oxide free copper
- Tightly woven
- Fast wicking
- Environmentally stable
- ESD safe bobbins for 1.5m size
- NSF – Non-food Compounds Program Listed

Applications:

- Solder removal
- Reworking and repair of circuit boards
- Benchtop repair and service
- Surface mount assembly touch up

We offer a choice of three types of desoldering braid:

FINE BRAID SUPER WICK (400 SERIES)

- RMA flux
- Economical

NO CLEAN SUPER WICK (400-NS SERIES)

- No Clean flux
- Flux residue is non-conductive and non-corrosive

LEAD FREE SUPER WICK (400-LF SERIES)

- Designed for use with lead free solder
- No-clean flux with high activation temperature
- Flux residue is non-conductive and non-corrosive

SuperWick™ Product Selection Chart

Cat. Number	Type	Width		Length		EDS Safe	Colour Code
		in	mm	ft	m		
423	Fine Braid	1/25	1.0	5	1.5	Yes	White
424	Fine Braid	1/16	1.5	5	1.5	Yes	Yellow
442	Fine Braid	1/16	1.5	25	7.5	No	Yellow
452	Fine Braid	1/16	1.5	50	15	No	Yellow
424-NS	No Clean	1/16	1.5	5	1.5	Yes	Yellow
424-LF	Lead-free	1/16	1.5	5	1.5	Yes	Yellow
425	Fine Braid	1/12	2.0	5	1.5	Yes	Green
443	Fine Braid	1/12	2.0	25	7.5	No	Green
453	Fine Braid	1/12	2.0	50	15	No	Green
463	Fine Braid	1/12	2.0	100	30	No	Green
425-NS	No Clean	1/12	2.0	5	1.5	Yes	Green
425-NS	No Clean	1/12	2.0	5	1.5	Yes	Green
453-NS	No Clean	1/12	2.0	50	15	No	Green
425-LF	Lead-free	1/12	2.0	5	1.5	Yes	Green
426	Fine Braid	1/10	2.5	5	1.5	Yes	Blue
444	Fine Braid	1/10	2.5	25	7.5	no	Blue
454	Fine Braid	1/10	2.5	50	15	no	Blue
464	Fine Braid	1/10	2.5	100	25	no	Blue
426-NS	No Clean	1/10	2.5	5	1.5	Yes	Blue
454-NS	No Clean	1/10	2.5	50	15	No	Blue
426-LF	Lead-free	1/10	2.5	5	1.5	Yes	Blue
427	Fine Braid	1/8	3.0	5	1.5	Yes	Brown

Available Packaging



5 ft / 1.5 m spool



50 ft / 15 m spool



25 ft / 7.5 m spool



100 ft / 30 m spool