



### Main

|                                    |                      |
|------------------------------------|----------------------|
| Accessory / separate part category | Cabling accessory    |
| Accessory / separate part type     | Pre-wired connectors |
| Series name                        | General purpose      |

### Complementary

|                                |  |
|--------------------------------|--|
| Electrical connection          | M12, 4 pins (included earth pin) straight female connector |
| Cable connector fixing         | Screw-on   |
| Collar material                | Metal  |
| Status LED                     | Without  |
| Cable length                   | 10 m   |
| Cable outer diameter           | 5.7 mm   |
| Cable composition              | 4 x 0.34 mm <sup>2</sup>                                   |
| Wire insulation material       | PUR  |
| [Ue] rated operational voltage | 250 V AC<br>300 V DC                                       |
| [In] rated current             | 4 A  |
| Contact resistance             | 5000 µOhm  |
| Insulating resistance          | 1 GΩ   |
| Product weight                 | 0.5 kg   |

### Environment

|                                       |  |
|---------------------------------------|--|
| IP degree of protection               | IP65<br>IP67<br>IP69K                        |
| Product certifications                | cULus  |
| Ambient air temperature for operation | -40...80 °C (static)<br>-5...80 °C (flexing) |
| Ambient air temperature for storage   | -40...80 °C                                  |


Offer Sustainability

|                                  |   |
|----------------------------------|---|
| Sustainable offer status         | Green Premium product   |
| RoHS (date code: YYWW)           | Compliant - since 0649 - Schneider Electric declaration of conformity<br><a href="#">Schneider Electric declaration of conformity</a> |
| REACH                            | Reference not containing SVHC above the threshold<br><a href="#">Reference not containing SVHC above the threshold</a>                |
| Product environmental profile    | Available<br><a href="#">Product Environmental Profile</a>  |
| Product end of life instructions | Available<br><a href="#">End of Life Information</a>  |

Contractual warranty

|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Dimensions

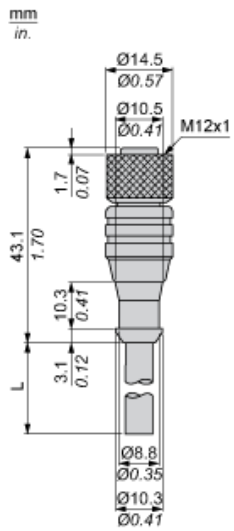


L : Length of cable

---

Connections and Schemes

---

Connector

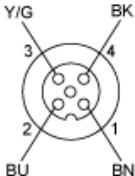

- BU : Blue
- BN : Brown
- BK : Black
- Y/G : Yellow / Green