


# Product data sheet

## Characteristics

# XZCPA0566L5

pre-wired connectors XZ - straight female - M8 - 3 pins - cable PUR 5m

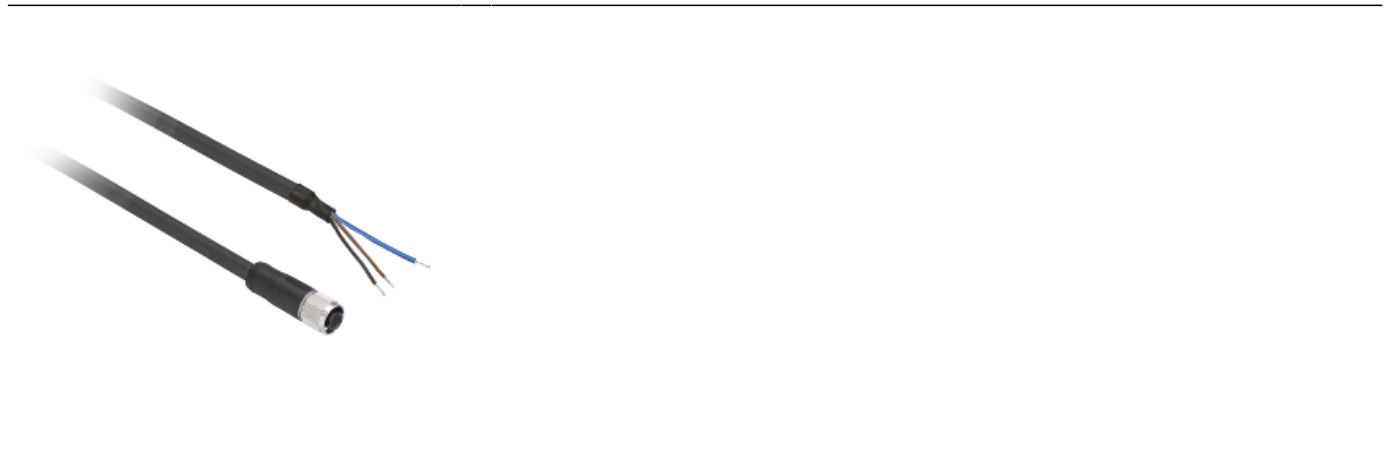

### Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	Application

### Complementary

Electrical connection	M8, 3 pins straight female connector
Cable connector fixing	Screw-on
Collar material	Stainless steel 316L
Status LED	Without
Cable length	5 m
Cable outer diameter	5 mm
Cable composition	3 x 0.34 mm <sup>2</sup>
Wire insulation material	PUR
[Ue] rated operational voltage	75 V DC
[In] rated current	4 A
Contact resistance	5000 µOhm
Insulating resistance	1 GΩ
Product weight	0.175 kg

### Environment

IP degree of protection	IP68
Ambient air temperature for operation	-25...85 °C (static)
Ambient air temperature for storage	-35...100 °C


### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0601 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
------------------------	---

### Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

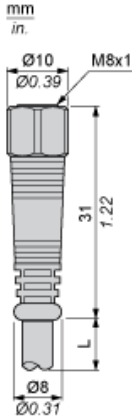


L : Length of cable

---

Connections and Schemes

---

Connector

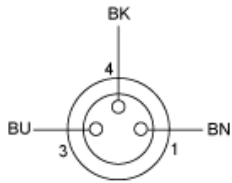

BU : Blue  
BN : Brown  
BK : Black