



## Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Jumper cable

## Complementary

Jumper cable end 1	M12 male, :4 pins (straight), fixing: screw-on
Jumper cable end 2	M12 female, :4 pins (straight), fixing: screw-on
Cable composition	4 x 0.34 mm <sup>2</sup>
Cable length	1 m
Wire insulation material	PUR
Cable outer diameter	5.2 mm
[Ue] rated operational voltage	250 V AC 300 V DC
[In] rated current	4 A
Insulation resistance	>= 1000 MOhm
Resistance across terminals	<= 5000 mOhm
Product weight	0.065 kg

## Environment

IP degree of protection	IP65 IP69K IP67
Product certifications	cULus
Ambient air temperature for operation	-35...90 °C (static) -5...90 °C (flexing)
Ambient air temperature for storage	-35...100 °C

## Offer Sustainability


Sustainable offer status	Green Premium product
--------------------------	-----------------------

RoHS (date code: YYWW)	Compliant - since 0649 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold <a href="#">Reference not containing SVHC above the threshold</a>
Product environmental profile	Available <a href="#">Product Environmental Profile</a>
Product end of life instructions	Available <a href="#">End of Life Information</a>

**Contractual warranty**

Warranty period	18 months
-----------------	-----------

Dimensions

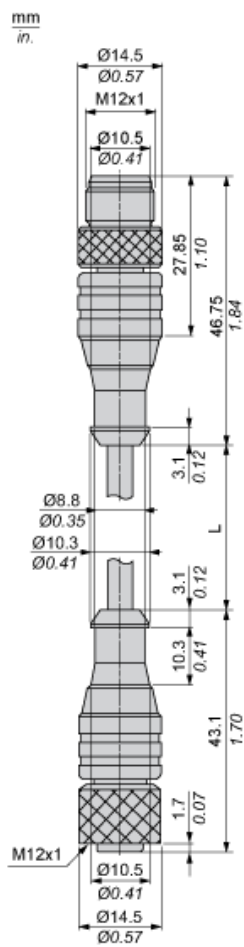


L : Length of cable

---

## Connections and Schemes

---

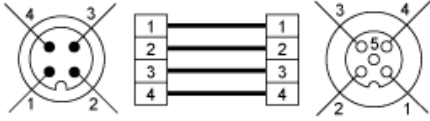

XZCR1511041C1 is replaced by:

---



### Application XZCR1511041C2

jumper cable XZ - male straight M12 4-pin - female straight M12 4-pin - PUR 2m

Qty 1

Reason for Substitution: End of life | Substitution date: 07 January 2005

---