



Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Straight male connector M12, 5 pins
Collar material	Metal
Status LED	Without
Cable connection	Spring / wire size $\leq 0.5 \text{ mm}^2$ / clamping capacity 4...8 mm

Complementary

Cable connector fixing	Screw-on
[Ue] rated operational voltage	30 V AC 36 V DC
[In] rated current	4 A
Enclosure material	Metal
Insulating resistance	$> 1000 \text{ G}\Omega$
Contact resistance	$\leq 8000 \mu\text{Ohm}$
Product weight	0.02 kg

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-40...85 °C


Offer Sustainability

RoHS (date code: YYWW)	Will be compliant on 4Q2013 Will be compliant on 4Q2013
------------------------	--

Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

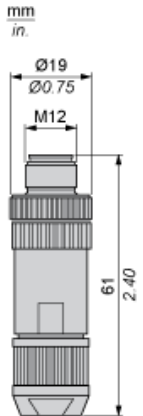

(1) Cable gland : no. 7 plastic (Pg 7)

Connections and Schemes

