

# Product data sheet

## Characteristics

# XZCC8FCM40S

female, M8, 4-pin, elbowed connector - cable gland M9.5 x 1



### Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Elbowed female connector M8, 4 pins
Collar material	Metal
Status LED	Without
Cable connection	Solder terminal / wire size $\leq 0.25 \text{ mm}^2$ / clamping capacity $\leq 5 \text{ mm}$

### Complementary

Cable gland type	M9.5
Cable connector fixing	Screw-on
[Ue] rated operational voltage	60 V AC 75 V DC
[In] rated current	4 A
Enclosure material	Plastic
Insulating resistance	$> 1 \text{ G}\Omega$
Contact resistance	$\leq 5000 \mu\text{Ohm}$
Product weight	0.01 kg

### Environment

IP degree of protection	IP67
Ambient air temperature for operation	-40...85 °C


### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0545 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
------------------------	---

### Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

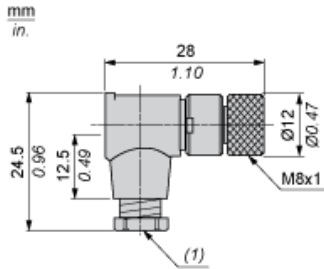

(1) Cable gland : M9.5 x 1

---

Connections and Schemes

---

