

Product data sheet

Characteristics

XZCC8FDM40S

female, M8, 4-pin, straight connector - cable gland
M9.5 x 1



Main

| | |
|------------------------------------|--|
| Accessory / separate part category | Cabling accessories |
| Accessory / separate part type | Connector |
| Electrical connection | Straight female connector M8, 4 pins |
| Collar material | Metal |
| Status LED | Without |
| Cable connection | Solder terminal / wire size $\leq 0.25 \text{ mm}^2$ / clamping capacity $\leq 5 \text{ mm}$ |

Complementary

| | |
|--------------------------------|---------------------------|
| Cable gland type | M9.5 |
| Cable connector fixing | Screw-on |
| [Ue] rated operational voltage | 60 V AC 75 V DC |
| [In] rated current | 4 A |
| Enclosure material | Plastic |
| Insulating resistance | $> 1 \text{ G}\Omega$ |
| Contact resistance | $\leq 5000 \mu\text{Ohm}$ |
| Product weight | 0.01 kg |

Environment

| | |
|---------------------------------------|-------------|
| IP degree of protection | IP67 |
| Ambient air temperature for operation | -40...85 °C |


Offer Sustainability

| | |
|------------------------|---|
| RoHS (date code: YYWW) | Compliant - since 0545 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity |
|------------------------|---|

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Dimensions

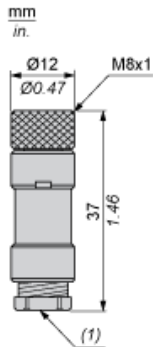

(1) Cable gland : M9.5 x 1

Connections and Schemes

