

TM-I
TM-I 12 MM WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com


Process reliability: TM-I

TM-I inlay tags have a guide tab which allows them to slide easily into the transparent sleeves from the type TM. The MultiMark TM-I markers should not be used together with the CLI T sleeves. We currently optimize the usability of the transparent sleeves from the type CLI T. Once the tag is in place, the tab is snapped off at the predetermined break point. The ready-assembled sleeves can then be simply pushed over the conductors. Your benefits: large quantities can be efficiently pre-assembled in a single step.

Your benefits with MultiMark

- Compact, practice-oriented range of products
- Quickly printed and assembled
- Reliable identification of your connections
- Excellent material properties

General ordering data

Type	TM-I 12 MM WS
Order No.	2005440000
Version	TM-I, Insert markers, 12 x 4 mm, white
GTIN (EAN)	4050118390278
Qty.	2,000 pc(s).
compatible printer	2430920000 2448870000 1140490000

Data sheet

TM-I TM-I 12 MM WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	4 mm	Width (inches)	0.157 inch
Height	12 mm	Height (inches)	0.472 inch
Net weight	0.161 g		

General data

Colour	white	Halogen	No
Material	Polyester	Number per roll	2,000
Operating temperature range	-40...150 °C	UL 94 flammability rating	HB
Width	4 mm		

Conductor and cable markers

Halogen	No
---------	----

Classifications

ETIM 5.0	EC001530	ETIM 6.0	EC001530
eClass 6.2	27-40-04-01	eClass 9.0	27-40-04-01
eClass 9.1	27-40-04-01		

Approvals

ROHS	Conform
------	---------

Downloads


Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet

TM-I
TM-I 12 MM WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

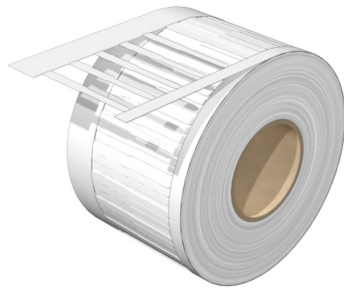

**TM-I
TM-I 12 MM WS**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

Ink ribbons THM MMP



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
RIBBON MM 76/360 SW	2005080000	Ink ribbon	4050118389951	1 pc(s).

Accessories / replacement parts



Our marking systems can be used to quickly and reliably label connector markers, conductor and cable markers, device markers and labels. The M-Print® PRO software enables rapid and easy identification of your electrical equipment. You can design, label and order your marking materials professionally and quickly. Frames, barcodes, graphics or photos are easily incorporated. The versatile data conversion routines enable quick and flexible data integration. The Weidmüller PrintJet ADVANCED, MCP Plus and MCP Basic printers and the THM series printers are available for printing.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
THM MMP ROLLER 115	1357420000		4050118160314	1 pc(s).