

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731120145](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT High Voltage Contact, Male, Straight, PCB Through Hole, 0.80µm Gold Plating

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	D-Sub Products
Series	173112
Brochure Order No	987651-9941
Contact Type	High Voltage
Exclude SD Check	Yes
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
UPC	889056489003

Physical


Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Insulator	PTFE
Material - Retaining Clip	PEI
Net Weight	0.400/g
Orientation	Straight
Packaging Type	Bag
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Plating min - Termination	0.800µm
Temperature Range - Operating	-55° to +125°C
Termination Style	Through Hole

Electrical

Current - Maximum per Contact	2.0A
-------------------------------	------

Material Info

Engineering Number	FMV005P107K
--------------------	-------------

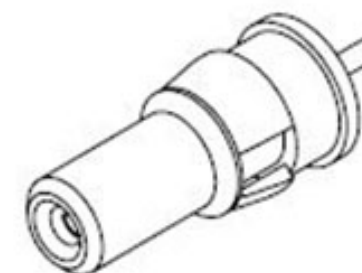

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[173112 Series](#)

Use With

FCT Mixed Layout Connectors