
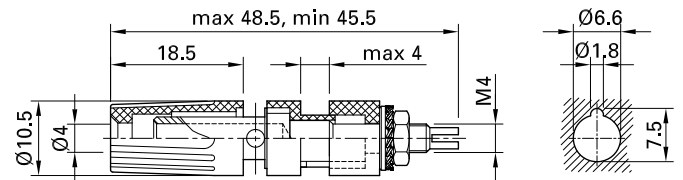


PK4-T

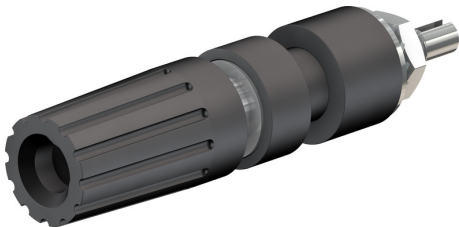

Item number 23.0330-*

Insulated, Ø 4 mm, rigid, and insulated head undetachable. Ø 2.5 mm cross hole for quick wire connection. Machined brass. For mounting, with anti-rotation lug, in front panels upto 4 mm thick. Connection: Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 VAC, 35 A / 60 VDC, 35 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Colours *	20 21 22 23 24 25 29
Thread	M4
Test accessory acc. to	IEC EN 61010-2-030