


THB.402.D2E

TeeTube 3+3 Pole Screw - end barrier contact 7mm to 13.5mm on one gland 8mm to 17mm on the other gland, 4 mm max conductor size IP68 32A 450V 3 cable entries

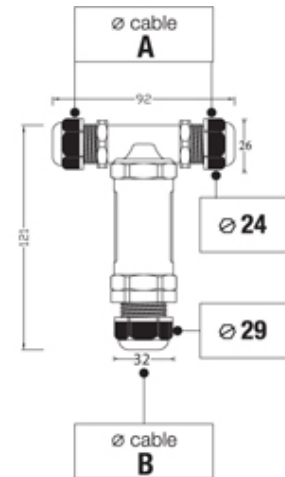

SPECIFICATION

| | |
|--|------------------|
| Cable Entries | 3 |
| Number of Poles | 3+3 |
| Terminal Type | Multiple contact |
| Body Material | PA66 / TPE |
| IP Rating | 68 |
| Max Conductor Size (Sq mm) | 4 |
| Max Current (A) | 32 |
| Max Voltage (V) | 450 |
| Minimum Temp Rating °C | -40 |
| Maximum Temp Rating °C | 125 |
| Minimum Cable Diameter (mm) | 7 |
| Maximum Cable Diameter (mm) | 13.5 |
| Secondary Minimum Cable Diameter (mm) | 8 |
| Secondary Maximum Cable Diameter (mm) | 17 |
| Fixing System | Cable |
| Temperature "T" Rating | T85 |