

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0717420006](#)
Status: **Active**
Overview: 1.00mm Mezzanine (IEEE 1386)
Description: 1.00mm Mezz (IEEE 1386) Receptacle, Surface Mount, Dual Row, Vertical Stacking, 84 Circuits, 0.76µm Gold Plating, Tape and Reel Packaging

Documents:

[3D Model](#) [Packaging Specification PK-70873-063 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-71741-9999-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family PCB Receptacles
 Series [71742](#)
 Application Board-to-Board, Signal
 Overview [1.00mm Mezzanine \(IEEE 1386\)](#)
 Product Name 1.00mm Mezzanine (IEEE 1386)
 UPC 822348735341

Physical


Circuits (Loaded) 84
 Circuits (maximum) 84
 Color - Resin Natural
 Flammability 94V-0
 Glow-Wire Capable No
 Lock to Mating Part Yes
 Material - Metal Phosphor Bronze
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Material - Resin High Temperature Thermoplastic
 Net Weight 1.747/g
 Number of Rows 2
 Orientation Vertical
 PCB Locator Yes
 PCB Retention None
 PCB Thickness - Recommended 1.60mm
 Packaging Type Embossed Tape on Reel
 Pitch - Mating Interface 1.00mm
 Plating min - Mating 0.762µm
 Plating min - Termination 1.905µm
 Polarized to PCB No
 Robotic Placement Pick and Place Cap
 Surface Mount Compatible (SMC) N/A
 Temperature Range - Operating -55° to +85°C
 Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 1.0A
 Voltage - Maximum 100V

Solder Process Data

Duration at Max. Process Temperature (seconds) 040
 Lead-free Process Capability REFLOW
 Max. Cycles at Max. Process Temperature 003

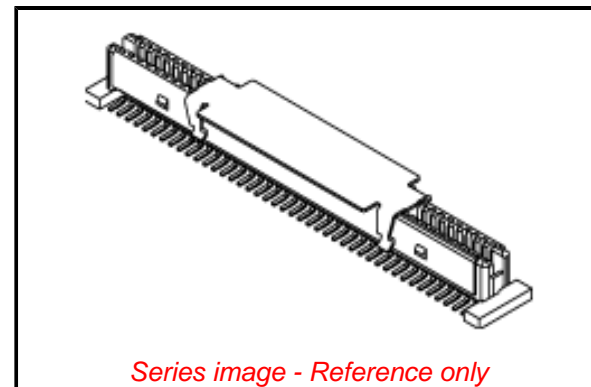

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[71742 Series](#)

Mates With

[71741](#) 1.00mm Mezz (IEEE 1386) Plug. Be sure to match like stack heights

Process Temperature max. C 260

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-70873-063
Product Specification	PS-71741-9999-001
Sales Drawing	717420000-000

This document was generated on 07/03/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION