


## VB RJ45 LaR-VB RJ45 LaR FRNC yellow 5.0m

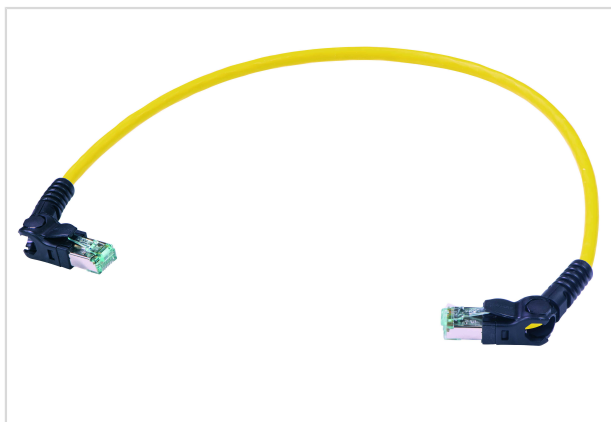

Part number	09 48 858 5587 050
Specification	VB RJ45 LaR-VB RJ45 LaR FRNC yellow 5.0m
HARTING eCatalogue	<a href="https://b2b.harting.com/09488585587050">https://b2b.harting.com/09488585587050</a>

### Identification

Category	Cable assemblies
Series	RJ45
Specification	Pre-assembled on both sides
Connector 1	HARTING VarioBoot RJ45 Preferred directions left/right
Connector 2	HARTING VarioBoot RJ45 Preferred directions left/right
Type of cable	Copper cable (round)
Description of the cable	Wiring 1:1 Flame retardant Halogen-free

### Version

Cable length	5 m
Number of cores	8
Core structure	4x 2 Twisted Pair

### Technical characteristics

Limiting temperature	-20 ... +60 °C unmoved 0 ... +60 °C moved
Degree of protection acc. to IEC 60529	IP20
Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz



Pushing Performance

## Technical characteristics

Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s

## Material properties

Material (cable)	FRNC (LSZH)
Colour (cable)	Yellow

## Specifications and approvals

Specifications	IEC 11801
	IEC 61156-6
	IEC 60332-1 Flame retardancy
	IEC 60754-2 Halogen freeness
	IEC 60754-2 Non corrosive
	IEC 61034 Low smoke

## Commercial data

Packaging size	1
Country of origin	Czechia
European customs tariff number	85444290
eCl@ss	Patch cord copper (data cable )