

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2065232122](#)  
**Status:** **Active**  
**Overview:** [Mini50 Connection Systems](#)  
**Description:** Mini50 Unsealed Receptacle, Dual Row, UL94-HB, with CPA, 12 Circuits, Polarization Option B, Gray

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-31301-538-001 \(PDF\)](#)  
[Product Specification 2065230000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Application Specification 2065230000-AS-000 \(PDF\)](#)

**General**

Product Family Crimp Housings  
Series [206523](#)  
Application Automotive, Power, Wire-to-Board  
Overview [Mini50 Connection Systems](#)  
Polarization B  
Product Name Mini50  
UPC 191128857062


**Physical**

Circuits (maximum) 12  
Color - Resin Gray  
Gender Receptacle  
Glow-Wire Capable No  
Keying to Mating Part Yes  
Lock to Mating Part Yes  
Material - Resin PBT  
Number of Rows 2  
Packaging Type Bag  
Panel Mount No  
Pitch - Mating Interface 2.00mm  
Pitch - Termination Interface 2.00mm  
Polarized to Mating Part Yes  
Stackable No  
Temperature Range - Operating -40° to +100°C

**Material Info**

**Reference - Drawing Numbers**

Application Specification 2065230000-AS-000  
Packaging Specification PK-31301-538-001  
Product Specification 2065230000-PS-000  
Sales Drawing 2065230000-000

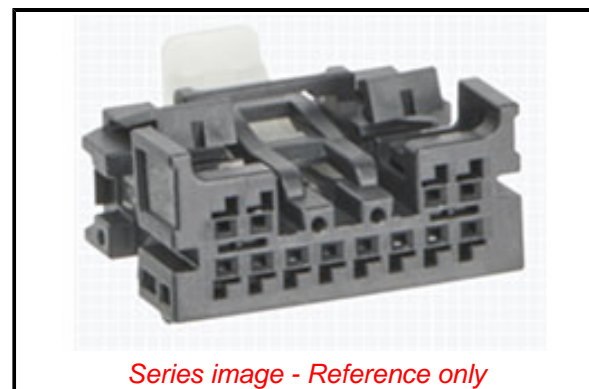

Series image - Reference only

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[206523](#) Series

**Mates With**

Mini50 Surface Mount Header [348978121](#), [348979121](#) <br> Mini50 Vertical Through-Hole Header [348250125](#), [348259125](#) <br> Mini50 Right-Angle Through-Hole Header [348260125](#), [348269125](#)

**Use With**

CTX50 Unsealed Terminals [560023](#)