

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2065232123](#)  
**Status:** **Active**  
**Overview:** [Mini50 Connection Systems](#)  
**Description:** Mini50 Unsealed Receptacle, Dual Row, UL94-HB, with CPA, 12 Circuits, Polarization Option C, Dark Gray

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-31301-538-001 \(PDF\)](#)  
[Product Specification 2065230000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Application Specification 2065230000-AS-000 \(PDF\)](#)

**General**

Product Family	Crimp Housings
Series	<a href="#">206523</a>
Application	Automotive, Power, Wire-to-Board
Overview	<a href="#">Mini50 Connection Systems</a>
Polarization	C
Product Name	Mini50
UPC	191128857079


**Physical**

Circuits (maximum)	12
Color - Resin	Gray (Dark)
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +100°C

**Material Info**

**Reference - Drawing Numbers**

Application Specification	2065230000-AS-000
Packaging Specification	PK-31301-538-001
Product Specification	2065230000-PS-000
Sales Drawing	2065230000-000

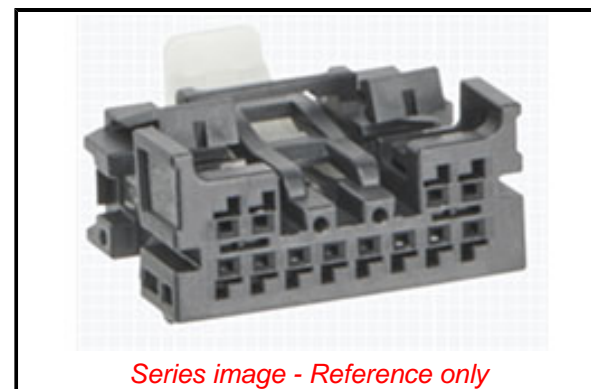

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[206523](#) Series

**Mates With**

Mini50 Surface Mount Header [348978122](#)  
, [348979122](#) <br> Mini50 Vertical Through-Hole Header [348250126](#) , [348259126](#) <br> Mini50 Right-Angle Through-Hole Header [348260126](#) , [348269126](#)

**Use With**

CTX50 Unsealed Terminals [560023](#)